


3m (10ft) Laptop Power Cord, EU Plug to C7, 2.5A 250V, 18AWG, Laptop Replacement Cord, Printer Power Cable, Laptop Charger Cord, Laptop Power Brick Cord, Black

**Product ID:** 752E-3M-POWER-LEAD

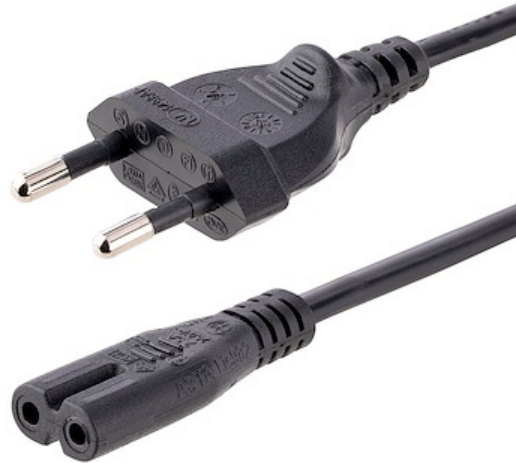

The 752E-3M-POWER-LEAD 3m Laptop Power Cord features one EU plug (CEE 7/16 Alternative II) and one non-polarized IEC 60320 C7 Connector. It is a suitable replacement cable for a Lenovo, IBM, or other compatible laptop power bricks that features a C8 inlet.

This product is backed for life, including free lifetime 24/5 multi-lingual technical assistance.

## Certifications, Reports and Compatibility



## Applications

### Features

- **AC POWER CABLE:** This 3m (9.8ft) 18AWG (0.75mm) flexible laptop power cord with EU Plug and IEC 60320 C7 connectors is suitable for power bricks featuring a C8 inlet. Workstation/home office use. Rated to carry 250V at 2.5A.
- **PERFORMANCE AND SAFETY:** Fully molded strain reliefs for durability. VDE approved cable. Fire Rating: VW-1. Jacket Rating: H03VVH2-F. 2 conductor Notebook Power Cable made with 100% Copper Wire.
- **SPECS:** 3m (9.8ft) Power Cable. EU Plug to IEC 60320 C7. 18AWG. 250V 2.5A (Max). Jacket Material: PVC. Jacket Dimensions: 3.4x5.6 mm (0.13x0.26in). Color: Black. Temperature Range: -10 to 35 (14 to 95F).

- **COMPATIBILITY:** AC Power Cord EU Plug works with European outlets IEC 60320 C7 connector works with C8 inlet power bricks for laptops/notebooks, monitors, scanners, printers, and more Replacement laptop power supply cable/lead

- **THE IT PRO'S CHOICE:** Designed and built for IT Professionals, this laptop charger cord is backed for life, including free lifetime 24/5 multi-lingual technical assistance

---

#### Hardware

Warranty	Lifetime
Number of Conductors	2
Connector Plating	Nickel
Cable Jacket Material	PVC - Polyvinyl Chloride
Fire Rating	VW-1 Rated

---

#### Connector(s)

Connector A	1 - CEE 7/16 Power (Europlug)
Connector B	1 - IEC 60320 C7 Power (Non-polarized)

---

#### Power

Input Voltage	250 AC
Input Current	2.5 A

---

#### Environmental

Operating Temperature	-10 to 35C (14 to 95F)
Storage Temperature	-15 to 70C (5 to 158F)
Humidity	5%RH ~ 95%RH

---

#### Physical Characteristics

Color	Black
Wire Gauge	0.75mm <sup>2</sup>
Cable Length	9.8 ft [3 m]
Product Length	1.4 in [3.5 cm]
Product Width	118.1 in [300.0 cm]

Product Height	0.6 in [1.5 cm]
Weight of Product	4.5 oz [127.0 g]

---

**Packaging Information**

Package Quantity	1
Package Length	5.7 in [14.5 cm]
Package Width	11.4 in [29.0 cm]
Package Height	1.6 in [4.0 cm]
Shipping (Package) Weight	4.8 oz [135.0 g]

---

**What's in the Box**

Included in Package	1 - 3m Standard Laptop Power Cord - EU to C7
---------------------	--

---

***\*Product appearance and specifications are subject to change without notice.***