


2m (6ft) Laptop Power Cord, EU Plug to C7, 2.5A 250V, 18AWG, Laptop Replacement Cord, Printer Power Cable, Laptop Charger Cord, Laptop Power Brick Cord

Product ID: 752E-2M-POWER-LEAD

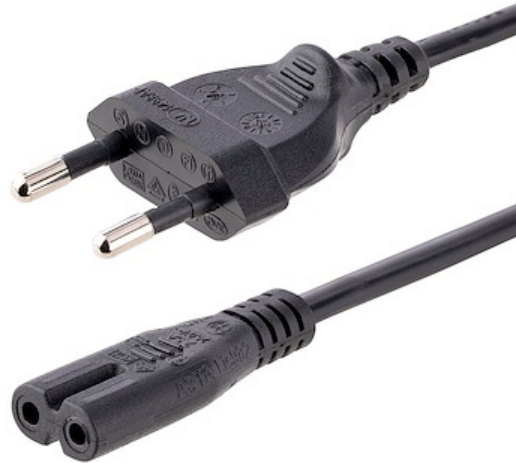

The 752E-2M-POWER-LEAD 2m Laptop Power Cord features one EU plug (CEE 7/16 Alternative II) and one non-polarized IEC 60320 C7 Connector. It is a suitable replacement cable for a Lenovo, IBM, or other compatible laptop power bricks that feature a C8 inlet.

This product is backed for life, including free lifetime 24/5 multi-lingual technical assistance.

Certifications, Reports and Compatibility



Applications

Features

- **AC POWER CABLE:** This 2m (6.5ft) 18AWG (0.75mm) flexible laptop power cord with EU Plug and IEC 60320 C7 connectors is suitable for power bricks featuring a C8 inlet. Workstation/home office use. Rated to carry 250V at 2.5A.
- **PERFORMANCE AND SAFETY:** Fully molded strain reliefs for durability. VDE approved cable. Fire Rating: VW-1. Jacket Rating: H03VVH2-F. 2 conductor Notebook Power Cable made with 100% Copper Wire.
- **SPECS:** 2m (6.5ft) Power Cable. EU Plug to IEC 60320 C7. 18AWG. 250V 2.5A (Max). Jacket Material: PVC. Jacket Dimensions: 3.4x5.6 mm. Color: Black. Temperature Range: -10 to 35 (-14 to 95F).

- **COMPATIBILITY:** AC Power Cord EU Plug works with European outlets IEC 60320 C7 connector works with C8 inlet power bricks for laptops/notebooks, monitors, scanners, printers, and more Replacement laptop power supply cable/lead

- **THE IT PRO'S CHOICE:** Designed and built for IT Professionals, this laptop charger cord is backed for life, including free lifetime 24/5 multi-lingual technical assistance

Hardware

Warranty	Lifetime
Number of Conductors	2
Connector Plating	Nickel
Cable Jacket Material	PVC - Polyvinyl Chloride
Fire Rating	VW-1 Rated

Connector(s)

Connector A	1 - CEE 7/16 Power (Europlug)
	1 - IEC 60320 C7 Power (Non-polarized)

Power

Input Voltage	250 AC
Input Current	2.5 A

Environmental

Operating Temperature	-10 to 35C (14 to 95F)
Storage Temperature	-15 to 70C (5 to 158F)
Humidity	5%RH ~ 95%RH

Physical Characteristics

Color	Black
Wire Gauge	0.75mm ²
Cable Length	6.6 ft [2 m]
Product Length	1.4 in [3.5 cm]
Product Width	78.7 in [200.0 cm]

Product Height	0.6 in [1.5 cm]
Weight of Product	3.2 oz [91.0 g]

Packaging Information

Package Quantity	1
Package Length	5.7 in [14.5 cm]
Package Width	11.4 in [29.0 cm]
Package Height	1.6 in [4.0 cm]
Shipping (Package) Weight	3.5 oz [99.0 g]

What's in the Box

Included in Package	1 - 2m Standard Laptop Power Cord - EU to C7
---------------------	--

****Product appearance and specifications are subject to change without notice.***