


## 4U Universal VESA LCD Monitor Mounting Bracket for 19-inch Rack or Cabinet - TAA Compliant - Cold-Pressed Steel Bracket

**Product ID:** RKLCDKBK

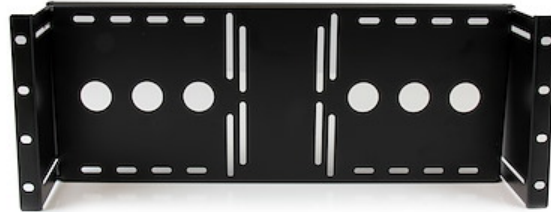

The RKLCDKBK Universal VESA LCD Monitor Mounting Bracket for 19in Rack or Cabinet lets you mount almost any retail LCD or Touch screen panel into a server/storage rack/cabinet. This TAA compliant product adheres to the requirements of the US Federal Trade Agreements Act (TAA), allowing government GSA Schedule purchases.

The LCD mounting bracket is made of solid cold pressed steel (SPCC), is designed to support 100mm and 75mm VESA mounted LCD panels, and meets ANSI/EIA RS-310-D standards rack mounting. A unique adjustable design enables an LCD panel to be mounted into the cabinet at various depths - allowing the rack/cabinet door to be closed.

The LCD mounting bracket also supports wall-mounted LCD installation, by inverting the adjustable bracket or by adding this bracket to a wall mount bracket or rack, such as the 6U (10 inch) Wallmount Bracket for 19" Rack Equipment (WALLMOUNT6) or 8U Open Frame Wall Mount Equipment Rack (RK812WALLO).

Backed by a StarTech.com Lifetime warranty.

### Certifications, Reports and Compatibility



### Applications

- Ideal for installing a retail LCD monitor into an existing Rack or Cabinet solution
- Use for uptime/process monitoring with big screens over 19" when mounted outwards
- Adding a monitoring display to a security rack or cabinet

- Installing a touch screen display into a rack or cabinet
- Mounting an LCD monitor or TV to the wall

## Features

- **STURDY DESIGN:** The LCD mounting bracket made of solid cold pressed steel (SPCC), is designed to support 100mm & 75mm VESA mounted LCD panels, and meets ANSI/EIA RS-310-D standards rack mounting
- **ADJUSTABLE DEPTH:** A unique adjustable design enables an LCD panel to be mounted into the AV rack cabinet at various depths, allowing the rack/cabinet door to be closed
- **ADDED FUNCTIONALITY:** The rackmount monitor bracket supports wall-mounted LCD installations by inverting or adding this bracket to a wall mount bracket or rack, such as the 6U Wall mount Bracket
- **TAA COMPLIANT:** This TAA compliant Universal VESA LCD Monitor Mounting Bracket adheres to the requirements of the US Federal Trade Agreements Act (TAA), allowing government GSA Schedule purchases
- **THE IT PRO'S CHOICE:** Designed and built for IT Professionals, this LCD mounting bracket is backed for life, including free lifetime 24/5 multi-lingual technical assistance

---

### Hardware

Warranty	Lifetime
Frame Type	Steel
U Height	4U
Cable Management	No
Industry Standards	EIA RS310-D

---

### Physical Characteristics

Color	Black
Material	Steel
Internal Width	17.3 in [43.9 cm]
Product Length	4.5 in [11.3 cm]
Product Width	19.0 in [48.3 cm]
Product Height	7.0 in [17.8 cm]
Weight of Product	3.6 lb [1.7 kg]

Maximum Mounting Depth 3.5 in [8.9 cm]

Minimum Mounting Depth 0.0 in [0 cm]

---

**Packaging Information**

Package Quantity	1
Package Length	18.3 in [46.6 cm]
Package Width	7.6 in [19.2 cm]
Package Height	2.1 in [5.4 cm]
Shipping (Package) Weight	4.1 lb [1.9 kg]

---

**What's in the Box**

Included in Package	2 - mounting brackets
	1 - LCD bracket
	8 - M5 cage nuts
	8 - M5 screws
	4 - M4 x 10mm LCD mounting screws
	4 - M5 x 10mm bracket screws
	4 - washers
	1 - instruction manual

---

***\*Product appearance and specifications are subject to change without notice.***