

**Surface-mount Ceramic Multilayer Capacitors (RoHS compliant & Halogen Free)**


CC0100500000SB000

Commodity CC01005 Sample Box

Spec Sheet

**Scope**

This is a qualified Multi-layer Ceramic Capacitor for use in General Electronic equipment.

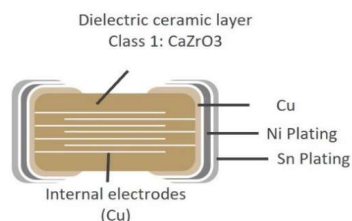

No.	Part NO.	Size	TC	Cap.	Volt.	Tol	QTY	No.	Part NO.	Size	TC	Cap.	Volt.	Tol	QTY
1	CC0100BRNPO8BNR50	01005	NPO	0.5pF	25V	±0.1pF	80	22	CC0100JRNPO8BN390	01005	NPO	39pF	25V	±5%	80
2	CC0100BRNPO8BNR75	01005	NPO	0.75pF	25V	±0.1pF	80	23	CC0100JRNPO8BN470	01005	NPO	47pF	25V	±5%	80
3	CC0100CRNPO8BN1R0	01005	NPO	1.0pF	25V	±0.25pF	80	24	CC0100JRNPO8BN560	01005	NPO	56pF	25V	±5%	80
4	CC0100CRNPO8BN1R2	01005	NPO	1.2pF	25V	±0.25pF	80	25	CC0100JRNPO8BN680	01005	NPO	68pF	25V	±5%	80
5	CC0100CRNPO8BN1R5	01005	NPO	1.5pF	25V	±0.25pF	80	26	CC0100JRNPO8BN820	01005	NPO	82pF	25V	±5%	80
6	CC0100CRNPO8BN1R8	01005	NPO	1.8pF	25V	±0.25pF	80	27	CC0100JRNPO8BN101	01005	NPO	100pF	25V	±5%	80
7	CC0100CRNPO8BN2R2	01005	NPO	2.2pF	25V	±0.25pF	80	28	CC0100KRX7R7BB221	01005	X7R	220pF	16V	±10%	80
8	CC0100CRNPO8BN2R7	01005	NPO	2.7pF	25V	±0.25pF	80	29	CC0100KRX7R7BB271	01005	X7R	270pF	16V	±10%	80
9	CC0100CRNPO8BN3R3	01005	NPO	3.3pF	25V	±0.25pF	80	30	CC0100KRX7R7BB331	01005	X7R	330pF	16V	±10%	80
10	CC0100CRNPO8BN3R9	01005	NPO	3.9pF	25V	±0.25pF	80	31	CC0100KRX7R7BB471	01005	X7R	470pF	16V	±10%	80
11	CC0100CRNPO8BN4R7	01005	NPO	4.7pF	25V	±0.25pF	80	32	CC0100KRX7R7BB561	01005	X7R	560pF	16V	±10%	80
12	CC0100CRNPO8BN5R6	01005	NPO	5.6pF	25V	±0.25pF	80	33	CC0100KRX7R7BB681	01005	X7R	680pF	16V	±10%	80
13	CC0100CRNPO8BN6R8	01005	NPO	6.8pF	25V	±0.25pF	80	34	CC0100KRX7R7BB102	01005	X7R	1nF	16V	±10%	80
14	CC0100CRNPO8BN8R2	01005	NPO	8.2pF	25V	±0.25pF	80	35	CC0100KRX7R7BB122	01005	X7R	1.2nF	16V	±10%	80
15	CC0100JRNPO8BN100	01005	NPO	10pF	25V	±5%	80	36	CC0100KRX5R6BB222	01005	X5R	2.2nF	10V	±10%	80
16	CC0100JRNPO8BN120	01005	NPO	12pF	25V	±5%	80	37	CC0100KRX5R6BB472	01005	X5R	4.7nF	10V	±10%	80
17	CC0100JRNPO8BN150	01005	NPO	15pF	25V	±5%	80	38	CC0100KRX5R6BB103	01005	X5R	10nF	10V	±10%	80
18	CC0100JRNPO8BN180	01005	NPO	18pF	25V	±5%	80	39	CC0100MRX5R5BB223	01005	X5R	22nF	6.3V	±20%	80
19	CC0100JRNPO8BN220	01005	NPO	22pF	25V	±5%	80	40	CC0100MRX5R5BB473	01005	X5R	47nF	6.3V	±20%	80
20	CC0100JRNPO8BN270	01005	NPO	27pF	25V	±5%	80	41	CC0100MRX5R5BB104	01005	X5R	100nF	6.3V	±20%	80
21	CC0100JRNPO8BN330	01005	NPO	33pF	25V	±5%	80	42	CC0100KRX5R5BB104	01005	X5R	100nF	6.3V	±10%	80