

Surface-mount Ceramic Multilayer Capacitors (RoHS compliant & Halogen Free)


CQ010050000SB000

High Frequency CQ01005 Sample Box

Spec Sheet

Scope

This is a qualified Multi-layer Ceramic Capacitor for use in General Electronic equipment.

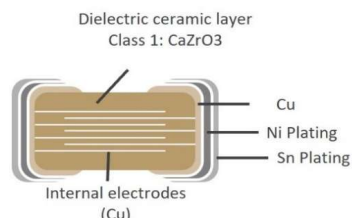

No.	Part. NO.	Size	Dielectric	Cap.	Volt.	Tol	Qty	No.	Part. NO.	Size	Dielectric	Cap.	Volt.	Tol	Qty
1	CQ0100BRNPO8BNR10	01005	NPO	0.1pF	25V	±0.1pF	80	22	CQ0100BRNPO8BN3R3	01005	NPO	3.3pF	25V	±0.1pF	80
2	CQ0100ARNPO8BNR20	01005	NPO	0.2pF	25V	±0.05pF	80	23	CQ0100BRNPO8BN3R6	01005	NPO	3.6pF	25V	±0.1pF	80
3	CQ0100ARNPO8BNR30	01005	NPO	0.3pF	25V	±0.05pF	80	24	CQ0100BRNPO8BN3R9	01005	NPO	3.9pF	25V	±0.1pF	80
4	CQ0100ARNPO8BNR40	01005	NPO	0.4pF	25V	±0.05pF	80	25	CQ0100BRNPO8BN4R0	01005	NPO	4.0pF	25V	±0.1pF	80
5	CQ0100ARNPO8BNR50	01005	NPO	0.5pF	25V	±0.05pF	80	26	CQ0100BRNPO8BN4R3	01005	NPO	4.3pF	25V	±0.1pF	80
6	CQ0100ARNPO8BNR60	01005	NPO	0.6pF	25V	±0.05pF	80	27	CQ0100BRNPO8BN4R7	01005	NPO	4.7pF	25V	±0.1pF	80
7	CQ0100ARNPO8BNR70	01005	NPO	0.7pF	25V	±0.05pF	80	28	CQ0100BRNPO8BN5R0	01005	NPO	5.0pF	25V	±0.1pF	80
8	CQ0100ARNPO8BNR80	01005	NPO	0.8pF	25V	±0.05pF	80	29	CQ0100CRNPO8BN5R6	01005	NPO	5.6pF	25V	±0.25pF	80
9	CQ0100ARNPO8BNR90	01005	NPO	0.9pF	25V	±0.05pF	80	30	CQ0100CRNPO8BN6R0	01005	NPO	6.0pF	25V	±0.25pF	80
10	CQ0100ARNPO8BN1R0	01005	NPO	1.0pF	25V	±0.05pF	80	31	CQ0100CRNPO8BN6R2	01005	NPO	6.2pF	25V	±0.25pF	80
11	CQ0100ARNPO8BN1R1	01005	NPO	1.1pF	25V	±0.05pF	80	32	CQ0100CRNPO8BN6R8	01005	NPO	6.8pF	25V	±0.25pF	80
12	CQ0100ARNPO8BN1R2	01005	NPO	1.2pF	25V	±0.05pF	80	33	CQ0100CRNPO8BN7R0	01005	NPO	7.0pF	25V	±0.25pF	80
13	CQ0100ARNPO8BN1R3	01005	NPO	1.3pF	25V	±0.05pF	80	34	CQ0100CRNPO8BN7R5	01005	NPO	7.5pF	25V	±0.25pF	80
14	CQ0100ARNPO8BN1R5	01005	NPO	1.5pF	25V	±0.05pF	80	35	CQ0100CRNPO8BN8R0	01005	NPO	8.0pF	25V	±0.25pF	80
15	CQ0100ARNPO8BN1R6	01005	NPO	1.6pF	25V	±0.05pF	80	36	CQ0100CRNPO8BN8R2	01005	NPO	8.2pF	25V	±0.25pF	80
16	CQ0100ARNPO8BN1R8	01005	NPO	1.8pF	25V	±0.05pF	80	37	CQ0100CRNPO8BN9R0	01005	NPO	9.0pF	25V	±0.25pF	80
17	CQ0100ARNPO8BN2R0	01005	NPO	2.0pF	25V	±0.05pF	80	38	CQ0100CRNPO8BN9R1	01005	NPO	9.1pF	25V	±0.25pF	80
18	CQ0100ARNPO8BN2R2	01005	NPO	2.2pF	25V	±0.05pF	80	39	CQ0100JRNPO8BN100	01005	NPO	10pF	25V	±5%	80
19	CQ0100ARNPO8BN2R4	01005	NPO	2.4pF	25V	±0.05pF	80	40	CQ0100JRNPO8BN120	01005	NPO	12pF	25V	±5%	80
20	CQ0100ARNPO8BN2R7	01005	NPO	2.7pF	25V	±0.05pF	80	41	CQ0100JRNPO8BN130	01005	NPO	13pF	25V	±5%	80
21	CQ0100ARNPO8BN3R0	01005	NPO	3.0pF	25V	±0.05pF	80	42	CQ0100JRNPO8BN150	01005	NPO	15pF	25V	±5%	80