

Surface-mount Ceramic Multilayer Capacitors (RoHS compliant & Halogen Free)


CQ0201000000SB000

High Frequency CQ0201 Sample Box

Spec Sheet

Scope

This is a qualified Multi-layer Ceramic Capacitor for use in General Electronic equipment.

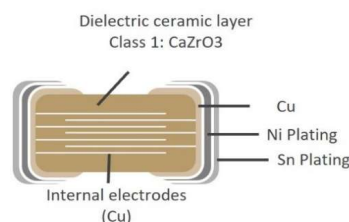

No.	Part. NO.	Size	Dielectric	Cap.	Volt.	Tol	Qty	No.	Part. NO.	Size	Dielectric	Cap.	Volt.	Tol	Qty
1	CQ0201BRNPO9BNR10	0201	NPO	0.1pF	50V	±0.1pF	80	24	CQ0201BRNPO9BN3R9	0201	NPO	3.9pF	50V	±0.1pF	80
2	CQ0201ARNPO9BNR20	0201	NPO	0.2pF	50V	±0.05pF	80	25	CQ0201BRNPO9BN4R0	0201	NPO	4.0pF	50V	±0.1pF	80
3	CQ0201ARNPO9BNR30	0201	NPO	0.3pF	50V	±0.05pF	80	26	CQ0201BRNPO9BN4R3	0201	NPO	4.3pF	50V	±0.1pF	80
4	CQ0201ARNPO9BNR40	0201	NPO	0.4pF	50V	±0.05pF	80	27	CQ0201BRNPO9BN4R7	0201	NPO	4.7pF	50V	±0.1pF	80
5	CQ0201ARNPO9BNR50	0201	NPO	0.5pF	50V	±0.05pF	80	28	CQ0201BRNPO9BN5R0	0201	NPO	5.0pF	50V	±0.1pF	80
6	CQ0201ARNPO9BNR60	0201	NPO	0.6pF	50V	±0.05pF	80	29	CQ0201CRNPO9BN5R6	0201	NPO	5.6pF	50V	±0.25pF	80
7	CQ0201ARNPO9BNR70	0201	NPO	0.7pF	50V	±0.05pF	80	30	CQ0201CRNPO9BN6R0	0201	NPO	6.0pF	50V	±0.25pF	80
8	CQ0201ARNPO9BNR80	0201	NPO	0.8pF	50V	±0.05pF	80	31	CQ0201CRNPO9BN6R2	0201	NPO	6.2pF	50V	±0.25pF	80
9	CQ0201ARNPO9BNR90	0201	NPO	0.9pF	50V	±0.05pF	80	32	CQ0201CRNPO9BN6R8	0201	NPO	6.8pF	50V	±0.25pF	80
10	CQ0201ARNPO9BN1R0	0201	NPO	1.0pF	50V	±0.05pF	80	33	CQ0201CRNPO9BN7R0	0201	NPO	7.0pF	50V	±0.25pF	80
11	CQ0201ARNPO9BN1R1	0201	NPO	1.1pF	50V	±0.05pF	80	34	CQ0201CRNPO9BN7R5	0201	NPO	7.5pF	50V	±0.25pF	80
12	CQ0201ARNPO9BN1R2	0201	NPO	1.2pF	50V	±0.05pF	80	35	CQ0201CRNPO9BN8R0	0201	NPO	8.0pF	50V	±0.25pF	80
13	CQ0201ARNPO9BN1R3	0201	NPO	1.3pF	50V	±0.05pF	80	36	CQ0201CRNPO9BN8R2	0201	NPO	8.2pF	50V	±0.25pF	80
14	CQ0201ARNPO9BN1R5	0201	NPO	1.5pF	50V	±0.05pF	80	37	CQ0201CRNPO9BN9R0	0201	NPO	9.0pF	50V	±0.25pF	80
15	CQ0201ARNPO9BN1R6	0201	NPO	1.6pF	50V	±0.05pF	80	38	CQ0201CRNPO9BN9R1	0201	NPO	9.1pF	50V	±0.25pF	80
16	CQ0201ARNPO9BN1R8	0201	NPO	1.8pF	50V	±0.05pF	80	39	CQ0201JRNPO9BN100	0201	NPO	10pF	50V	±5%	80
17	CQ0201ARNPO9BN2R0	0201	NPO	2.0pF	50V	±0.05pF	80	40	CQ0201JRNPO9BN120	0201	NPO	12pF	50V	±5%	80
18	CQ0201ARNPO9BN2R2	0201	NPO	2.2pF	50V	±0.05pF	80	41	CQ0201JRNPO9BN150	0201	NPO	15pF	50V	±5%	80
19	CQ0201ARNPO9BN2R4	0201	NPO	2.4pF	50V	±0.05pF	80	42	CQ0201JRNPO9BN180	0201	NPO	18pF	50V	±5%	80
20	CQ0201ARNPO9BN2R7	0201	NPO	2.7pF	50V	±0.05pF	80	43	CQ0201JRNPO9BN220	0201	NPO	22pF	50V	±5%	80
21	CQ0201ARNPO9BN3R0	0201	NPO	3.0pF	50V	±0.05pF	80	44	CQ0201JRNPO9BN270	0201	NPO	27pF	50V	±5%	80
22	CQ0201BRNPO9BN3R3	0201	NPO	3.3pF	50V	±0.1pF	80	45	CQ0201JRNPO9BN330	0201	NPO	33pF	50V	±5%	80
23	CQ0201BRNPO9BN3R6	0201	NPO	3.6pF	50V	±0.1pF	80	46	CQ0201JRNPO9BN390	0201	NPO	39pF	50V	±5%	80