

Surface-mount Ceramic Multilayer Capacitors (RoHS compliant & Halogen Free)


HV888800000SB000

High Voltage ($\geq 500V$) Sample Box

Spec Sheet

Scope

This is a qualified Multi-layer Ceramic Capacitor for use in General Electronic equipment.

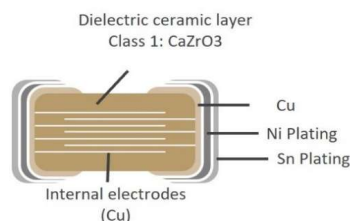

No.	Part NO.	Size	TC	Cap.	Volt.	Tol	Qty	No.	Part NO.	Size	TC	Cap.	Volt.	Tol	Qty
1	CC0805JRNPOBBN220	0805	NPO	22pF	500V	±5%	40	26	CC1206KKX7RCBB471	1206	X7R	470pF	1KV	±10%	40
2	CC0805JRNPOBBN470	0805	NPO	47pF	500V	±5%	40	27	CC1206KKX7RCBB102	1206	X7R	1nF	1KV	±10%	40
3	CC0805JRNPOBBN101	0805	NPO	100pF	500V	±5%	40	28	CC1206KKX7RCBB222	1206	X7R	2.2nF	1KV	±10%	40
4	CC0805JKNPOBBN102	0805	NPO	1nF	500V	±5%	40	29	CC1206KKX7RCBB472	1206	X7R	4.7nF	1KV	±10%	40
5	CC0805JRNPOZBN471	0805	NPO	470pF	630V	±5%	40	30	CC1206KKX7RCBB103	1206	X7R	10nF	1KV	±10%	40
6	CC0805JRNPOCBN100	0805	NPO	10pF	1KV	±5%	40	31	CC1206KKX7RDBB102	1206	X7R	1nF	2KV	±10%	40
7	CC0805JRNPOCBN470	0805	NPO	47pF	1KV	±5%	40	32	CC1206KKX7RDBB152	1206	X7R	1.5nF	2KV	±10%	40
8	CC0805KRX7RBBB471	0805	X7R	470pF	500V	±10%	40	33	CC1206KKX7RSBB102	1206	X7R	1nF	2.5KV	±10%	40
9	CC0805KRX7RBBB102	0805	X7R	1nF	500V	±10%	40	34	CC1210JKNPODBN470	1210	NPO	47pF	2KV	±5%	40
10	CC0805KRX7RBBB222	0805	X7R	2.2nF	500V	±10%	40	35	CC1210KKX7RBBB104	1210	X7R	100nF	500V	±10%	40
11	CC0805KKX7RBBB103	0805	X7R	10nF	500V	±10%	40	36	CC1210KKX7RZBB473	1210	X7R	47nF	630V	±10%	40
12	CC1206JRNPOCBN100	1206	NPO	10pF	1KV	±5%	40	37	CC1210KKX7RCBB223	1210	X7R	22nF	1KV	±10%	40
13	CC1206JKNPOCBN470	1206	NPO	47pF	1KV	±5%	40	38	CC1210KKX7RDBB102	1210	X7R	1nF	2KV	±10%	40
14	CC1206JKNPOCBN680	1206	NPO	68pF	1KV	±5%	40	39	CC1808JKNPOEBN100	1808	NPO	10pF	3KV	±5%	40
15	CC1206JKNPOCBN101	1206	NPO	100pF	1KV	±5%	40	40	CC1808JKNPOEBN680	1808	NPO	68pF	3KV	±5%	40
16	CC1206JKNPODBN220	1206	NPO	22pF	2KV	±5%	40	41	CC1808JKNPOEBN101	1808	NPO	100pF	3KV	±5%	40
17	CC1206JKNPODBN101	1206	NPO	100pF	2KV	±5%	40	42	CC1808KKX7RDBB102	1808	X7R	1nF	2KV	±10%	40
18	CC1206JKNPODBN221	1206	NPO	220pF	2KV	±5%	40	43	CC1808KKX7RDBB222	1808	X7R	2.2nF	2KV	±10%	40
19	CC1206KKX7RBBB102	1206	X7R	1nF	500V	±10%	40	44	CC1808KKX7REBB102	1808	X7R	1nF	3KV	±10%	40
20	CC1206KKX7RBBB222	1206	X7R	2.2nF	500V	±10%	40	45	CC1812JKNPODBN102	1812	NPO	1nF	2KV	±5%	20
21	CC1206KKX7RBBB103	1206	X7R	10nF	500V	±10%	40	46	CC1812JKNPOEBN330	1812	NPO	33pF	3KV	±5%	20
22	CC1206KKX7RZBB102	1206	X7R	1nF	630V	±10%	40	47	CC1812JKNPOEBN221	1812	NPO	220pF	3KV	±5%	20
23	CC1206KKX7RZBB103	1206	X7R	10nF	630V	±10%	40	48	CC1812KKX7RZBB104	1812	X7R	100nF	630V	±10%	20
24	CC1206KKX7RZBB223	1206	X7R	22nF	630V	±10%	40	49	CC1812KKX7RDBB472	1812	X7R	4.7nF	2KV	±10%	20
25	CC1206KKX7RZBB333	1206	X7R	33nF	630V	±10%	40	50	CC2220KKX7RZBB224	2220	X7R	220nF	630V	±10%	20