


Features

- Protects equipment users from harm
- Bright Nickel Chrome Plating
- Steel Finger guard
- Fixing centres 32mm by 32mm

Highland Finger Guard

Part Number: HIG-W40

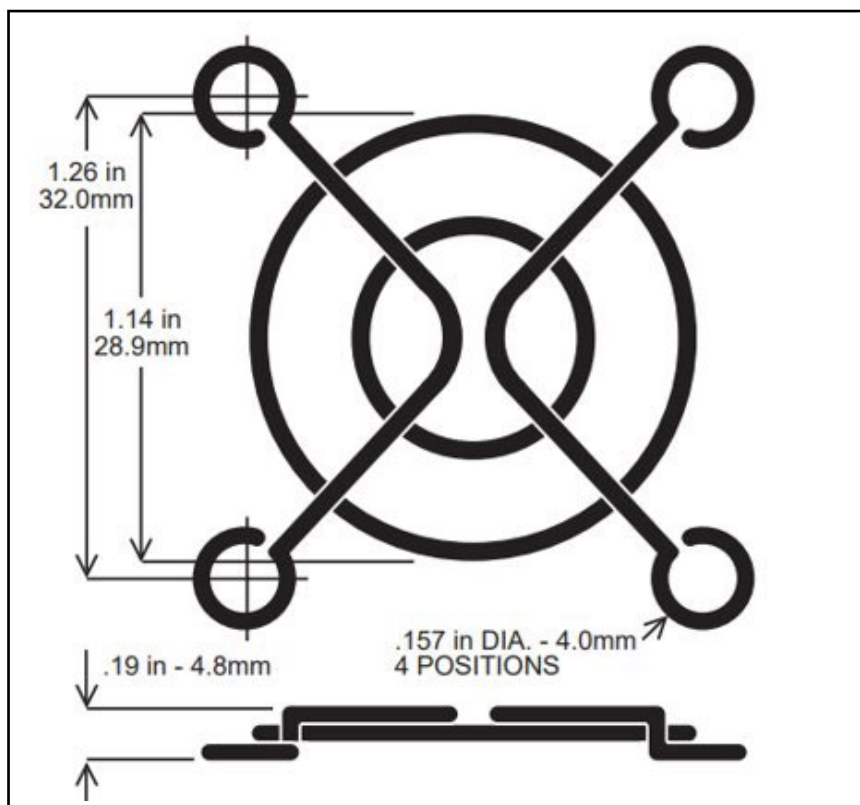

Product Description

- Our 40mm Fan wire finger guard protects the fan from damage and equipment users from harm.
- Made from high-quality C1008 Steel material for exceptional durability and longevity.
- Plated with bright nickel chrome for extra protection against corrosion and wear and tear.
- Ring diameter of 1.6mm and rib diameter of 1.6mm.
- Fixing centres 32mm x 32mm ± 0.5 mm, ensuring a perfect fit for your 40mm fan.
- RoHS compliant, ensuring safety and free from hazardous materials.
- Various plating styles are available upon request for a perfect finish.

General Specifications

| | |
|-----------------------------|---|
| Guard Type | 40mm wire guard |
| Frame Material | C1008 Steel |
| Frame Finish | Bright nickel chrome |
| For Use With | 9CRJ40, 9HVA40, 9CRA40, 9CRH40, 9CRE40, 9GAX40, 9GA40, 9HV40, 9GV40, 9CRD40, 9CRD40, 9WL40, 9WPA40, 9GA40, 109P40 |
| Weight (g) per part: | 44 |
| Tariff Code: | 84149000 |
| Guard Type | 40mm wire guard |

Mechanical Specifications

| | |
|-------------------------------|-------------|
| Fan Size | 40mm |
| Fixing centres | 32mm x 32mm |
| Length | 40mm |
| Width | 40mm |
| Thickness | 4.8mm |
| Mounting Hole Diameter | 4mm |

Approvals

| | |
|----------------------------------|----------------|
| Compliance/Certifications | RoHS Compliant |
|----------------------------------|----------------|

