




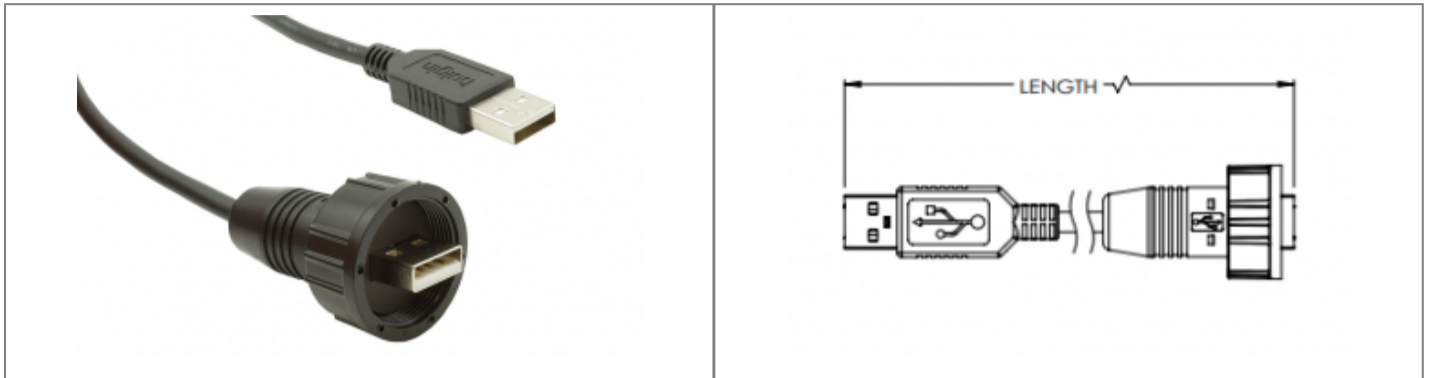


# PXP0020/A/0M50/A Datasheet

**Product Name // Flex USB A Male to USB A Male Cable  
Assembly 0.5m**

[View Product Page](#)



## // Product Description:

-  IP67 Male USB A to Male USB A
-  IP67 when mated
-  Mates with rear panel mount connectors PXP0023, PXM0023
-  USB 2.0 Performance
-  Length 0.5m

## // General Information:

Product Display Title:	Sealed USB Cable / Single Ended
Product Family:	Circular Data Connectors
Product Series:	20 Series USB
Body Colour:	Black
Body Material:	PVC
Body Material Type:	Plastic Body
Cable Length:	0.5m
Contact Pin Material:	Copper, Gold plated
Contact Type:	Plug Contact
Coupling Type:	Screw
Data Cable Type:	USB 2.0 Sealed A Plug to Standard A Plug
Diameter Over Coupling Ring Mm:	25.5mm
Durability:	1500
Fixing Nut Material:	Plastic
Flamability Rating:	UL94V-0
Function:	Flex to Standard Connector Double Ended Cable
Ip Rating:	IP67
Max Operating Temperature:	80°C
Min Operating Temperature:	-10°C
Number Of Contacts:	4 Contacts
Panel Cut Out:	20.8mm x 19.4mm
Rohs Compliant:	Yes
Sheath Colour:	Black
Sheath Material:	PVC
Thread Size:	13/16-28UN 2A
Voltage Max:	5V

### // Product PDF Links

 [20 Series USB Waterproof product...](#)

### // Product 3D CAD Model Links

 [PXP0020/A/0M50/A3D CAD Model](#)