


Category 6A 24 Port 0.5U Patch Panel

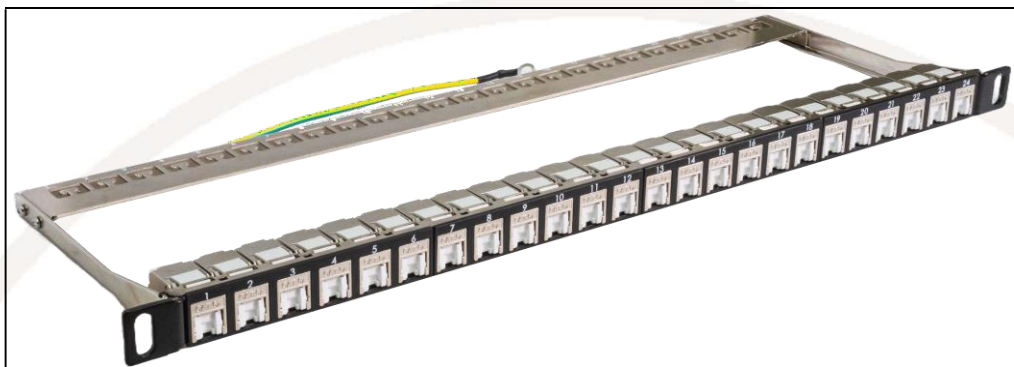

Category 6A 24 Port 0.5U STP Patch Panel (SGFtk0.5)

TUK's Category 6A 0.5U STP patch panel offers tried and tested top level performance in a compact package.

Features

- High performance compliant with ANSI/TIA 568 C.2 standard, performs to Category 6A standard (permanent link level)
- Compliant with IEC60512-99-002 – suitable for use with IEEE 802.3bt (4PPoE+) applications at up to 100W
- Fully shielded die-cast keystone body is robust as well as offering outstanding performance in eliminating alien cross-talk
- Provides quick and easy tool-less lever “butterfly style” termination
- Suitable for 0.51 – 0.65 mm/ 22 – 24 AWG stranded and solid wire
- Clear numbering on the front provides a quick, easy way to identify cable run
- Supplied with a removeable rear cable management bar, 2 sets of M6 black cage nuts and 270mm long earth wire (comes fitted)
- Sockets supplied with built in dustcover

Specifications

- Weight: 1367 g approx.
- Dimensions: 505 x 162 x 30 (W x D x H) approx.
- Colour:
 - front: black + silver
 - rear: silver

- **Material:**
 - Panel: cold-rolled steel with ABS plastic facia
 - Rear of panel and cable management: nickel plated
 - Contacts: 50 μ "/1.27 μ m gold plating over nickel over phosphor bronze
 - Keystone housing: Zinc alloy

Packaging: Supplied as a kit of 1 x FFK24mt0.5pt panel and 24 x SGKSje keystones in an individual carton

EAN: 5055386511409

Commodity Code: 85177090

Country of Origin: China


For further information on components, please see links below:

SGKSje <https://tuk.co.uk/product/category-6a-shielded-keystone-socket/>





FFK24mt0.5pt <https://tuk.co.uk/product/0-5u-24-port-unpopulated-keystone-panel/>

ROHS Compliant

Code: SGFtk0.5

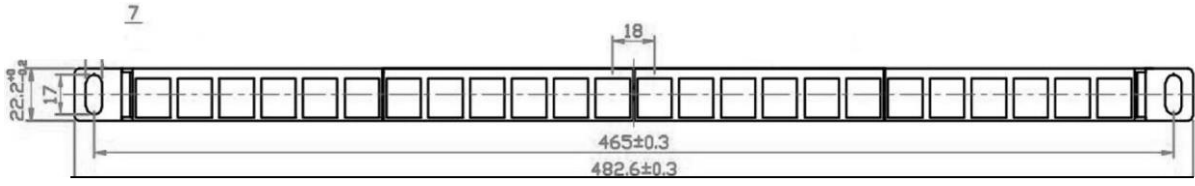

 Jo reHHHHHHHHHHHPHHHHHI---II-----JI---;n----JHI---;a d

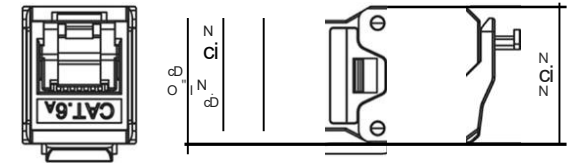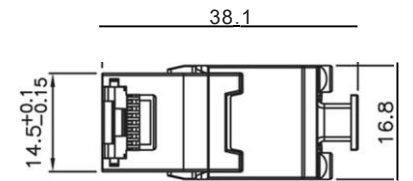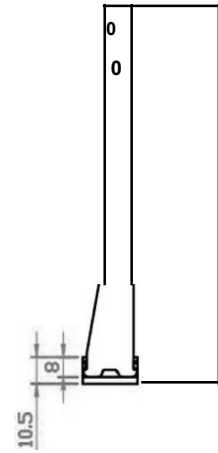

Supplied with 24 keystone sockets

an