

斯闊企業股份有限公司
普歲電子股份有限公司



S. Square Enterprise Co., Limited
Pro-Wave Electronics Corporation

新北市中和區中山路二段 348 巷 8 號 4 樓 P.O. Box 1-70 Chung Ho, Taiwan, ROC; Tel: (02)-22465101 Fax: Int'l +886-2-22465105

Model Number: 400ER18S

Specification:


| | |
|-----------------------|------------------------|
| Center Frequency | 40.0±1.0KHZ |
| Sensitivity | -67dB @ 0dB=1Volt/μbar |
| Bandwidth | 1.5KHZ @ -6dB |
| Capacitance | 2800±20%pF @ 1KHZ |
| Operation Temperature | -30° to +70°C |
| Storage Temperature | -40° to +80°C |
| Allowable Input Power | 0.2 Watt |

Model Number: 400ET18S

Specification:

| | |
|---|----------------------------|
| Center Frequency | 40.0±1.0KHZ |
| Sound Pressure Level Measured at 30cm,10Vrms Sine Wave input | 112dB @ 0dB re 0.0002 μbar |
| Bandwidth | 1.5KHZ @ -6dB |
| Capacitance | 2800±20%pF @ 1KHZ |
| Operation Temperature | -30° to +70°C |
| Storage Temperature | -40° to +80°C |
| Allowable Input Power | 0.2 Watt |

Test Circuit:

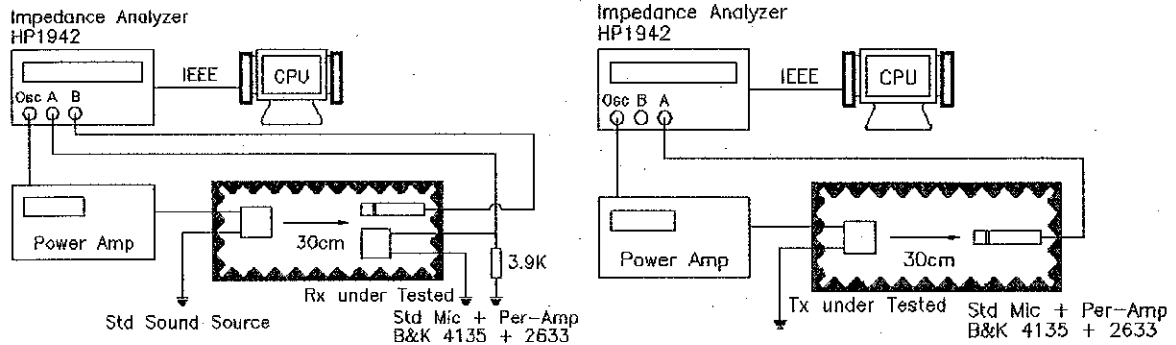

Dimensions: in mm

