

## Data Sheet | Item Number: 211-861

Conductor markers for thread-on mounting; for Smart Printer; 5 x 10.5 mm; white

<https://www.wago.com/211-861>



Color: ■ white

Similar to illustration

### Technical data

Suitable	for wire cross-section 0.75 ... 1.5 mm <sup>2</sup>
Marking method	Thermal transfer
Marking	plain
Delivery form	Roll
Delivery form configuration	1000 pcs/reel; 3 lines
Printing device	Smart Printer (thermal transfer printer)

### Physical data

Depth	0.22 mm
Marking surface	5 x 23 mm

### Mechanical data

Mounting type	Sliding on conductor
Smear resistance	in conjunction with 258-5005 Ink Ribbon

### Material data

Color	white
Material	Polyester
UV resistance	EN 60068-2-5:2010 Procedure B
Adhesive information	without adhesive
Halogen-free	Yes
Weight	165 g
Fire load	0 MJ

**Environmental requirements**

Ambient temperature (operation)	-40 ... +150 °C
Relative humidity	40 ... 50 %

**Commercial data**

Product Group	2 (Terminal Block Accessories)
eCl@ss 10.0	27-40-04-01
eCl@ss 9.0	27-40-06-29
ETIM 9.0	EC001530
ETIM 8.0	EC001530
PU (SPU)	1 pcs
Packaging type	Box
Country of origin	DE
GTIN	4050821688655
Customs tariff number	39269097900

**Environmental Product Compliance**

RoHS Compliance Status	Compliant, No Exemption
------------------------	-------------------------

**Downloads**

**Environmental Product Compliance**

<b>Compliance Search</b>			
Environmental Product Compliance 211-861			↓

**Documentation**

<b>Operating Instructions</b>			
211-861 Information on printing material	1	28.08.2020	pdf 1244,38 KB
			↓

**1 Compatible Products**

**1.1 Optional Accessories**

**1.1.1 Marking**


**1.1.1.1 Marking device**



**Item No.: 258-5000**  
 Thermal transfer printer; Smart Printer; for complete control cabinet marking; 300 dpi; With marking material

## Installation Notes

### Application

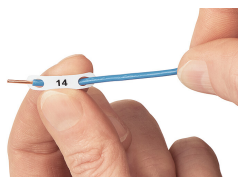

Conductor marker for thread-on mounting