

Data Sheet | Item Number: 211-862

Conductor markers for thread-on mounting; for Smart Printer; 7 x 10.5 mm; white

<https://www.wago.com/211-862>



Color: ■ white

Similar to illustration

Technical data

Suitable	for wire cross-section 2.5 ... 6 mm ²
Marking method	Thermal transfer
Marking	plain
Delivery form	Roll
Delivery form configuration	1000 pcs/reel; 3 lines
Printing device	Smart Printer (thermal transfer printer)

Physical data

Depth	0.22 mm
Marking surface	7 x 26 mm

Mechanical data

Mounting type	Sliding on conductor
Smear resistance	in conjunction with 258-5005 Ink Ribbon

Material data

Color	white
Material	Polyester
UV resistance	EN 60068-2-5:2010 Procedure B
Adhesive information	without adhesive
Halogen-free	Yes
Weight	156 g
Fire load	0.01 MJ

Environmental requirements

Ambient temperature (operation)	-40 ... +150 °C
Relative humidity	40 ... 50 %

Commercial data

Product Group	2 (Terminal Block Accessories)
eCl@ss 10.0	27-40-04-01
eCl@ss 9.0	27-40-06-29
ETIM 9.0	EC001530
ETIM 8.0	EC001530
PU (SPU)	1 pcs
Packaging type	Box
Country of origin	DE
GTIN	4050821688662
Customs tariff number	39269097900

Environmental Product Compliance

RoHS Compliance Status	Compliant, No Exemption
------------------------	-------------------------

Downloads

Environmental Product Compliance


Compliance Search

Environmental Product
Compliance 211-862



Documentation

Operating Instructions

211-861 Information on printing material	1 28.08.2020	pdf 1244,38 KB	
---	-----------------	-------------------	---

1 Compatible Products

1.1 Optional Accessories

1.1.1 Marking

1.1.1.1 Marking device




[Item No.: 258-5000](#)

Thermal transfer printer; Smart Printer; for complete control cabinet marking; 300 dpi; With marking material

Installation Notes

Application

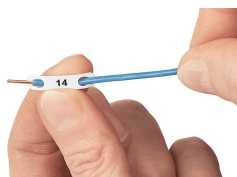

Conductor marker for thread-on mounting