

## BoVersa | Wall brackets



**BOV 12 WL 9005**

**Order no.: 48800305**

\* = Available on request.



### Characteristics

#### Colour of enclosure group

Black, similar to RAL 9005

#### Enclosure Material

Plastic parts PC UL 94 V-0 (material is flame-retardant, self-extinguishing and suitable for outdoor use; f1 listing in accordance with UL 746 C)

Aluminium parts GD Al Si 12


Seal PU foamed

Materials in accordance with requirement set R1 / R7 according to DIN EN 45545-2

Hazard Level HL3

For details, see Technical Information

### Product drawing

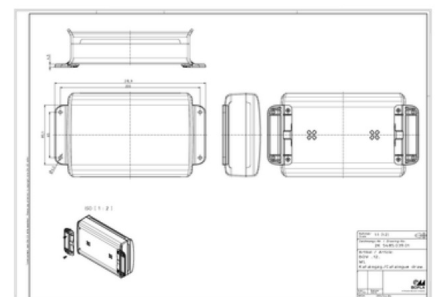

#### Scope of delivery

4 wall brackets (polycarbonate UL 94 V0), 4 screws

## Important!

---

To compensate for pressure when temperatures change and cause moisture in the enclosure, we recommend that you use a [pressure compensation](#) element.

In order to ensure that you can determine **the correct quantity of elements for your application**, we are providing you here with a DAE calculator.

[» Additional information](#)

## Technical documentation / Downloads

---

### Technical drawings

**3D product data in STEP format:**

48800305 BOV-12-WL-BoVersa-Wandlasche-9005.stp  
(817.0 KB)

**Product drawing in PDF format:**

48800305 BOV-12-WL-BoVersa-Wandlasche-9005.pdf  
(241.3 KB)

**Product drawing in DXF format:**

48800305 BOV-12-WL-BoVersa-Wandlasche-9005.dxf  
(2.4 MB)

### Product information

**BoVersa web Doppelseite-EN.pdf**

(458.1 KB)