

BoVersa | Wall brackets



BOV 19 WL 9005

Order no.: 48800605

* = Available on request.



Characteristics

Colour of enclosure group

Black, similar to RAL 9005

Enclosure Material

Plastic parts PC UL 94 V-0 (material is flame-retardant, self-extinguishing and suitable for outdoor use; f1 listing in accordance with UL 746 C)

Aluminium parts GD Al Si 12


Seal PU foamed

Materials in accordance with requirement set R1 / R7 according to DIN EN 45545-2

Hazard Level HL3

For details, see Technical Information

Product drawing

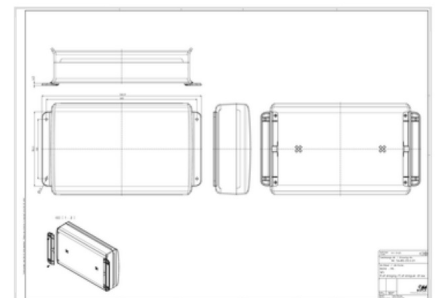

Scope of delivery

4 wall brackets (polycarbonate UL 94 V0), 4 screws

Important!

To compensate for pressure when temperatures change and cause moisture in the enclosure, we recommend that you use a [pressure compensation](#) element.

In order to ensure that you can determine **the correct quantity of elements for your application**, we are providing you here with a DAE calculator.

[» Additional information](#)

Technical documentation / Downloads

Technical drawings

3D product data in STEP format:

48800605 BOV-19-WL-BoVersa-Wandlasche-9005.stp
(793.3 KB)

Product drawing in PDF format:

48800605 BOV-19-WL-BoVersa-Wandlasche-9005.pdf
(245.6 KB)

Product drawing in DXF format:

48800605 BOV-19-WL-BoVersa-Wandlasche-9005.dxf
(2.4 MB)

Product information

BoVersa web Doppelseite-EN.pdf

(458.1 KB)