




Minitek® -

86730-301LF

OVERVIEW

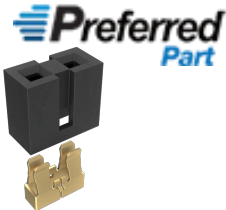

View Product Series

OVERVIEW

DESCRIPTION

Jumper, Single Row, 2 Position, 2.00mm (0.079in) Pitch, Black color, Gold plating 0.38µm

ENVIRONMENTAL COMPLIANCE

View Product Series

[Drawing](#)
[3D Model \(STP\)](#)
[Product Specification](#)
[Product Presentation](#)
[Datasheet BTB](#)
[Datasheet WTB](#)

DISTRIBUTOR STOCK CHECK

SYMBOL, FOOTPRINT & 3D

RELATED PARTS

PART SPECIFICATION DETAIL

The information below is for reference only. For more technical details, refer to product specification and application specification.

Color - Housing	Black	Csa file number	LR46923
Durability (Mating cycles)	50	Flammability Rating	UL 94 V-0
Housing Height	3.50mm (0.138in)	Material Contact	Phosphor Bronze
Material Housing	Glass-Filled PBT	# of Contacts	2

# of Rows	1	Operating Temperature Range	-55°C to +125°C
Packaging	Bag	Pitch	2.00mm (0.079in)
Plating Contact area	0.38µm (15µin) Gold	Resistance (Contact)	25mΩ
Resistance (Insulation)	100000MΩ min	Solder process	Compatible with Vapor-phase IR Reflow soldering Process
UI file number	E66906		
Current Rating	1A	Voltage Rating	200V

3D VIEW

