


## Product information

# 97 49 10

- Application: non-insulated tubular cable lugs and crimp terminals in accordance with DIN 46237 and non-insulated butt and crimp connectors in accordance with DIN 46341 0.75 / 1.5 / 2.5 mm<sup>2</sup>

### Crimping die

For non-insulated tube and crimp cable lugs and non-insulated butt and crimp connectors in accordance with DIN 46341

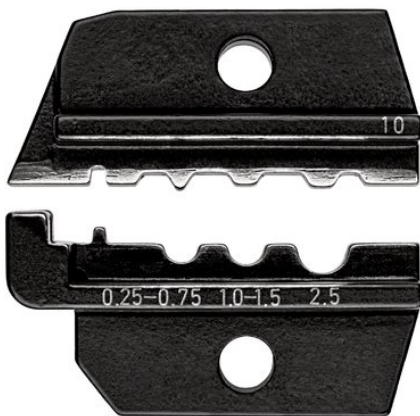

#### General

Article No.	97 49 10
EAN	4003773076896
Weight	37 g
Dimensions	12 x 32 mm
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

#### Technical details



Application	for non-insulated crimp
Capacity in square millimetres	0.25 — 2.5 mm <sup>2</sup>
AWG	24 — 14

*technical change and errors excepted*