


Product information

97 49 14

Crimping die

For non-insulated crimp

- Application: for non-insulated crimp terminals, tube and compression cable lugs in accordance with DIN 46234 and DIN 46235 and non-insulated crimp, butt and press connectors in accordance with DIN 46341 and DIN 46267 0.5-10 mm²

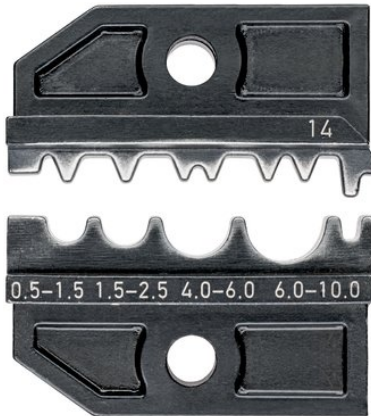

General

Article No.	97 49 14
EAN	4003773077756
Weight	37 g
Dimensions	50 x 17 mm
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details



Application	for non-insulated crimp
Capacity in square millimetres	0.5 — 10 mm ²
Number of crimp profiles	4
AWG	20 — 8

technical change and errors excepted