


Product information

97 49 04

Crimping die

For non-insulated, open plug type connectors
(2.8 + 4.8 mm width)

- Application: non-insulated open plug type connectors (plug width 2.8 + 4.8 mm) 0.1 - 2.5 mm²
- Application: for non-insulated, open lug connectors > Crimping die 1: 0.1 - 0.25 mm² - plug width 2.8 mm > Crimping die 2: 0.5 - 1.0 mm² - plug width 2.8 mm > Crimping die 3: 0.5 - 1.0 mm² - plug width 4.8 mm > Crimping die 4: 1.5 - 2.5 mm² - plug width 4.8 mm
- The additionally available locator 97 49 94 makes it easier to guide the contact during the crimping process
- Not suitable for special contact series such as Tyco Electronics, Molex, JST etc.

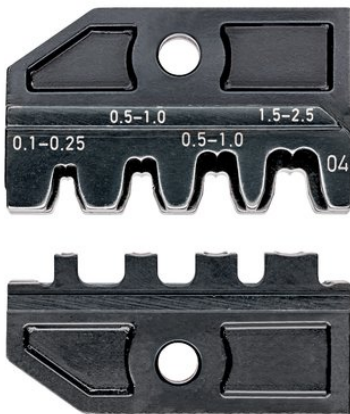

General

Article No.	97 49 04
EAN	4003773030850
Weight	42 g
Dimensions	50 x 10 mm
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details



Application	non-insulated open plug type connectors - plug width 2.8 + 4.8 mm
Capacity in square millimetres	0.1 — 2.5 mm ²
Number of crimp profiles	4
AWG	26 — 14

Accessories

97 49 94	Locator for 97 49 04 / 97 52 04 / 97 52 34,
----------	---

technical change and errors excepted