


Product information

97 49 05

Crimping die

For non-insulated open plug type connectors
(plug width 4.8 + 6.3 mm)

- Application: non-insulated open plug type connectors (plug width 4.8 + 6.3 mm) 0.5 - 6.0 mm²
- Application: for non-insulated, open lug connectors > Crimping die 1: 0.5 - 1.0 mm² - plug width 4.8 and 6.3 mm > Crimping die 2: 1.5 - 2.5 mm² - plug width 4.8 and 6.3 mm > Crimping die 3: 4.0 - 6.0 mm² - plug width 4.8 and 6.3 mm
- The additionally available locator 97 49 95 makes it easier to guide the contact during the crimping process
- Not suitable for special contact series such as Tyco Electronics, Molex etc.

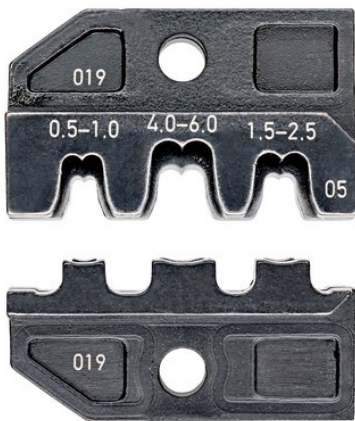

General

Article No.	97 49 05
EAN	4003773030867
Weight	46 g
Dimensions	50 x 10 mm
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details



Application	non-insulated open plug type connectors - plug width 4.8 + 6.3 mm
Capacity in square millimetres	0.5 — 6 mm ²
Number of crimp profiles	3
AWG	20 — 10

Accessories

97 49 95	Locator for 97 49 05 / 97 52 05 / 97 52 35,
----------	---------------------------------------------

technical change and errors excepted