


Product information

97 49 15

Crimping die

For plug connectors and non-insulated open plug-type connectors

- Application: Flag terminals and non-insulated, open plug type connectors (6.3 mm connector width) 1.25-2.5 + 3.0-6.0 mm²
- Application: crimping die 1: for non-insulated, open lug connectors with sided line terminal style A 1.5 + 2.5 mm, e. g. Klauke 3735 style B > Crimping die 2: 2.5 - 4.0 mm² - plug width 4.8 and 6.3 mm (straight version) > Crimping die 3: 4.5 - 6.0 mm² - plug width 4.8 and 6.3 mm (straight version)

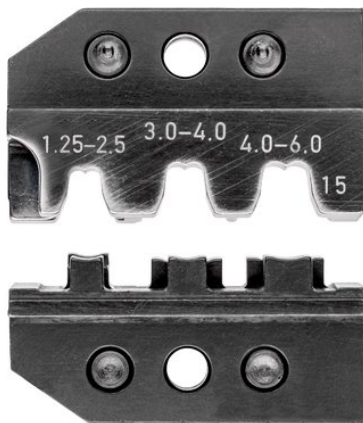

General

Article No.	97 49 15
EAN	4003773043164
Weight	56 g
Dimensions	50 x 17 mm
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details



Application	Non-insulated open plug type connectors with lateral conductor connection style A
Capacity in square millimetres	1.5 — 6 mm ²
Number of crimp profiles	2
AWG	16 — 10

technical change and errors excepted