


## Product information

# 97 49 50

### Crimping die

For coax connectors / car phone

- Application: coax connectors/car phone RG 58, 74, 188, 316 sleeves: 3.9, 5.4, 6.4, 2.1, 1.3, 0.95
- Function 1: crimping capacity hexagonal 3.25 mm
- Function 2: crimping capacity hexagonal 4.52 mm
- Function 3: crimping capacity hexagonal 5.4 mm
- Function 4: crimping capacity hexagonal 1.72 mm
- Function 5: crimping capacity hexagonal 1.07 mm
- Function 6: crimping capacity hexagonal 0.72 mm

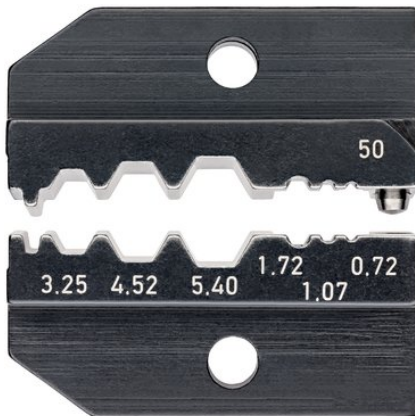

#### General

Article No.	97 49 50
EAN	4003773030966
Weight	48 g
Dimensions	50 x 17 mm
REACH compliant	contains SVHC
RoHS compliant	not applicable

#### Technical details



Application	Coax connectors RG 58, RG174, RG316, RG188
Number of crimp profiles	6
Capacity SW mm	3.25 / 4.52 / 5.4 / 1.72 / 1.07 / 0.72 mm

*technical change and errors excepted*