


Product information

97 49 08

- Application: insulated + non-insulated wire ferrules
- Approved crimping according to UL in conjunction with KNIPEX wire ferrules 97 99 330 - 399

Crimping die

For insulated and non-insulated wire ferrules

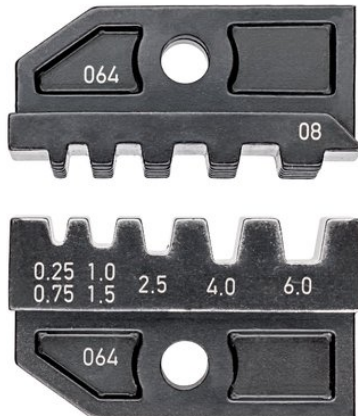

General

Article No.	97 49 08
EAN	4003773030874
Weight	49 g
Dimensions	50 x 17 mm
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details



Application	insulated and non-insulated wire ferrules
Capacity in square millimetres	0.25 — 6 mm ²
Number of crimp profiles	5
AWG	24 — 10

technical change and errors excepted