

CAB P 705027



Sample image

Order symbol : CAB P 705027

Product nr : 8104307

Description : Polyester cabinet


Remarks : Grey door

EAN : 6418074050045

El. number :

- Finland : 3424141
- Denmark : 8212018044
- Sweden : 2539825

Including : Cabinet base, door with PUR gasket, 3mm double bit lock(s) with transport and plastic key, screws for mounting plate/DIN-rail and wall fastening lugs with screws. Wall mounting screws not supplied.

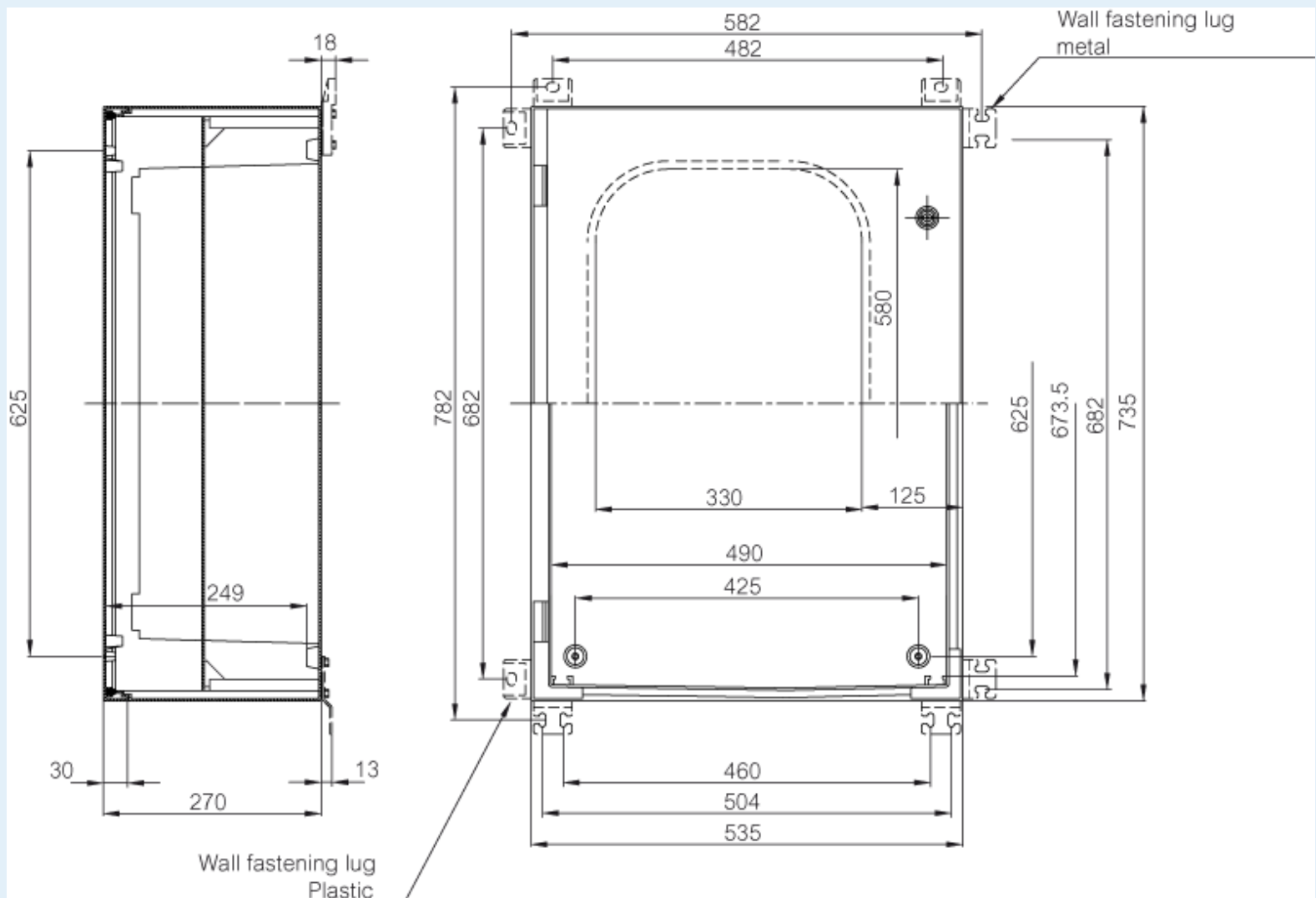

Dimensions :	Height	Width	Depth
mm :	700	500	270
inch :	27.56	19.69	10.63

Materials :

Material :	Glass Fiber Reinforced Polyester
Base colour :	RAL_7035
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

Temperatures :

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

Accessories :

FP 7050-4x22	Front Plate with DIN openings, for enclosures: (700 x 500 x 1)
MB CAB	Swing door kit (187 x 145 x 29)
MF 7050	Mounting Frame with DIN-rails, for enclosures: (700 x 500 x 1)
FP 7050-D	Swing door/Front plate, for enclosures: (700 x 500 x 1)
MPX 7050	Mounting Plate, for enclosures: (700 x 500 x 1)
MP 7050	Mounting plate, for enclosures: (700 x 500 x 3)
MPP 7050	Mounting Plate, for enclosures: (700 x 500 x 2)

Ratings :

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK10;
electrical_insulation :	Totally insulated
UV resistance :	UL 746C
Flammability Rating :	UL 94 HB
Glow Wire Test (IEC 695-2-1) °C :	960C