

# CAB PC 303018 G3B



Sample image

**Order symbol :** CAB PC 303018 G3B

**EAN :** 6418074020147

**Product nr :** 8113342



**El. number :**

**Description :** Cabinet, PC, Grey door

- Finland : 3424111
- Denmark : 8212019221
- Sweden : 2539969

**Remarks :** Lock on the long side

**Including :** Cabinet base, door with PUR gasket, 3mm double bit lock(s) with key, screws for mounting plate/DIN-rail and corner plugs.

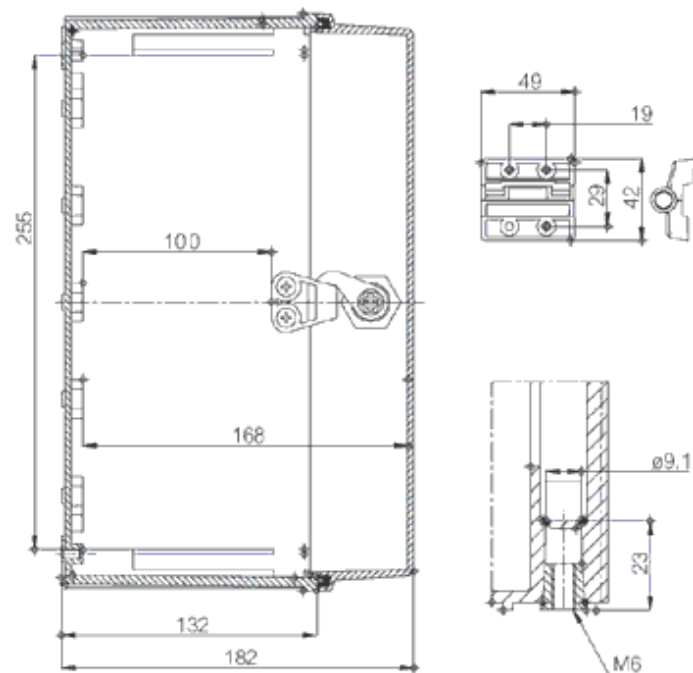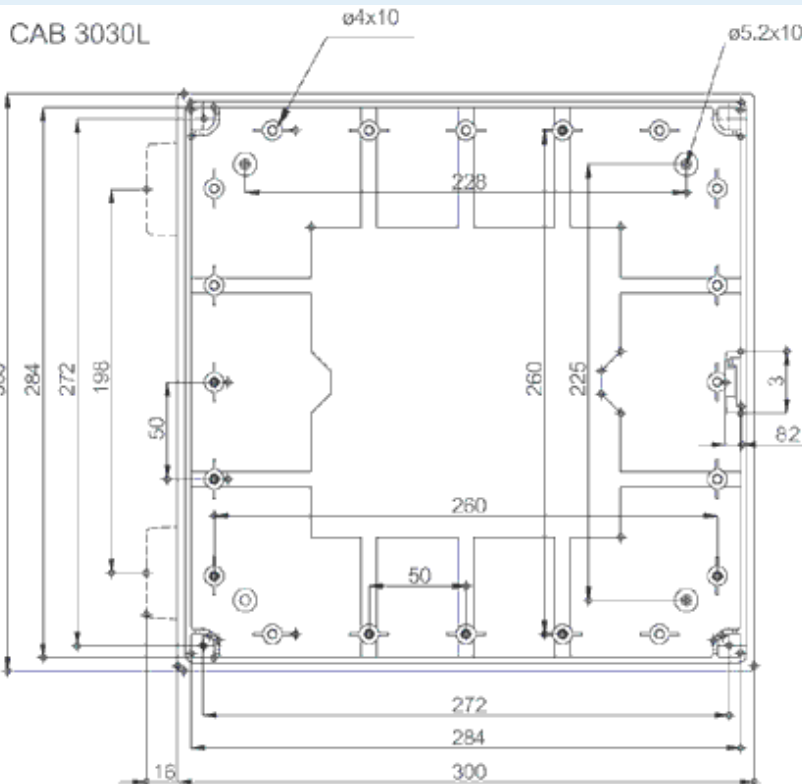

Dimensions :	Height	Width	Depth
mm :	300	300	180
inch :	11.81	11.81	7.09

**Materials :**

**Accessories :**

- EKIV 33 Mounting plate, for enclosures: (270 x 270 x 1.5)
- MB 12225 AL Swing door set (20 x 20 x 80)
- FP A 33 Swing-out door/Front plate (aluminium), for enclosures:

Material : Polycarbonate  
Base colour : RAL\_7035  
Cover colour : RAL 7035 -light grey  
Gasket material : Polyurethane

(268 x 268 x 1)

EKIV 27 DIN-35 Mounting rail, for enclosures:  
(266 x 35 x 1.5)

DRF 33 DIN rail frame set, for enclosures:

**Temperatures :**

Temperature °C (continuous) : -40 ... 80  
Temperature °F (continuous) : -40 ... 175

**Ratings :**

Ingress protection (EN 60529): IP65;  
Impact Resistance (EN 62262): IK08;  
electrical\_insulation : Totally insulated  
Halogen free (DIN/VDE 0472, Part 815) : Yes  
UV resistance : UL 746C  
Flammability Rating : UL 94 V0  
Glow Wire Test (IEC 695-2-1) °C : 960C

**Certificates :**

Certificate FI 40854