

TAM111107



Sample image

Order symbol : TAM111107

EAN : 6418074011435

Product nr : 5814021


El. number :

Description : Enclosure, ABS, metric knock-outs

- Denmark : 8212045266
- Sweden : 5814021

Remarks : Grey cover

Including : Base with PUR gasket and screws for mounting plate/DIN-rail. cover with polyamide cover screws and plastic hinges.

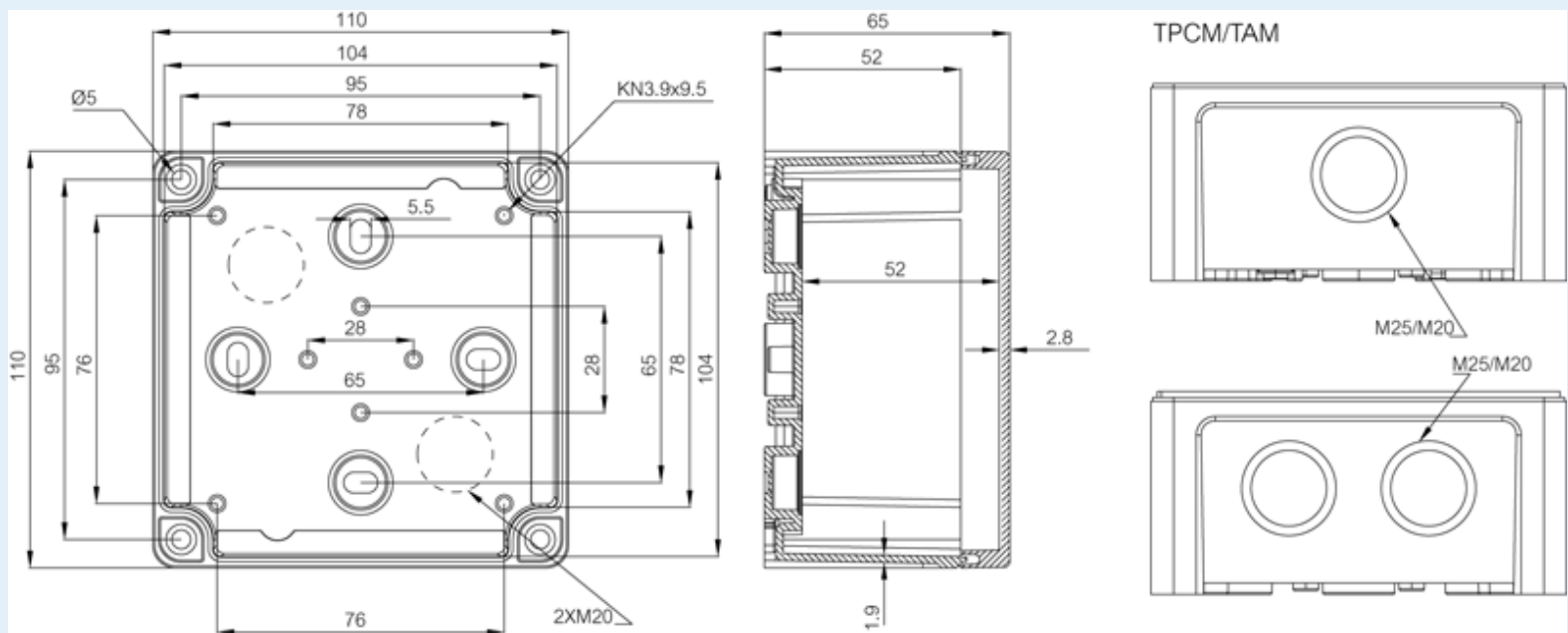

Dimensions :	Height	Width	Depth
mm :	110	110	65
inch :	4.33	4.33	2.56

Accessories :

FP 10674 Wall fastening lug (2 pcs) incl. screws

Materials :

Material : ABS

Ratings :

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK07;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	-
Flammability Rating :	UL 94 HB

Temperatures :

Temperature °F (continuous) : -40 ... 140

Glow Wire Test (IEC 695-2-1) °C :

650C

Certificates :

Certificate FI 40343