


# AOUS4/015 Datasheet

**Product Name // USB 3.2 Gen2 Active Optical Cable, A male to C male PVC jacket no screws 15m**

[View Product Page](#)

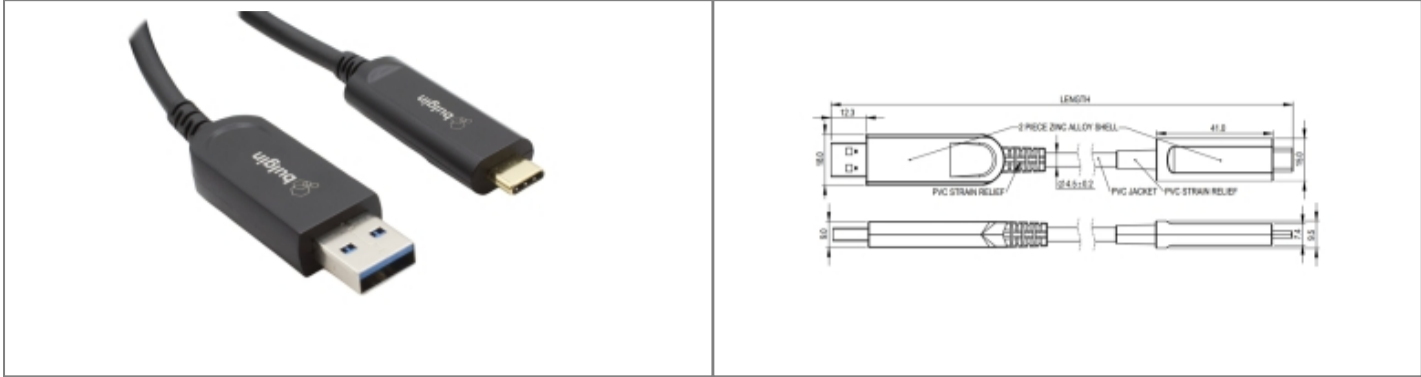

**// Product Description:**

- ⬢ USB 3.2 Gen2 Active Optical Cable, A male to C male PVC jacket no screws
- ⬢ Cable length 15m
- ⬢ Up to 10Gbps

**// General Information:**

Product Display Title:	USB 3.2 Cable
Product Family:	Data Connectors
Product Series:	AO Series USB
Body Colour:	Black
Body Material:	Zinc Alloy
Body Material Type:	Metal
Cable Length:	15m
Contact Type:	Plug Contact
Data Cable Type:	USB 3.2 Gen 2
Durability:	1000
Fibre Mode:	Multimode
Flamability Rating:	VW-1
Function:	USB 3.2 Cable
Max Operating Temperature:	50°C
Min Operating Temperature:	0°C
Rohs Compliant:	Yes
Sheath Colour:	Black
Sheath Material:	PVC
Voltage Max:	5.5V

**// Product PDF Links**

[AO Series USB product data](#)

**// Product 3D CAD Model Links**

[AOUS4/0153D CAD Model](#)