

25

2542 04



Modular connectors



Double modular socket, Cat. 6a, 8p8c (RJ45), straight version, with shielding

25

2542 04

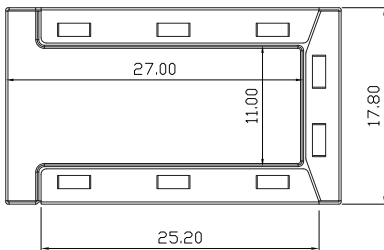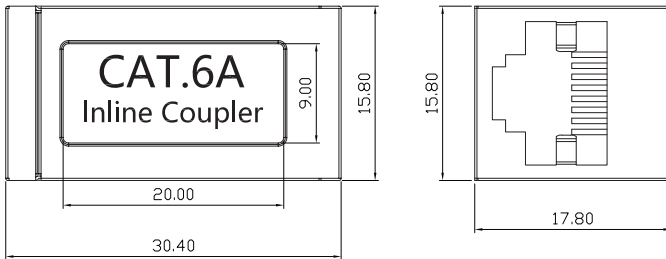

Environmental conditions

Temperature range 0 °C/+70 °C

Materials

Insulating body ABS
Contact CuSn, gold-plated
Housing/handle stainless steel

Mechanical data

Mating cycles ≥ 750

Electrical data (at T_{amb} 20 °C)

Contact resistance ≤ 20 m Ω
Rated current 1.5 A
Rated voltage 125 V AC RMS
Withstand voltage 750 V AC RMS/60 s
Insulation resistance 1 G Ω

Associated products

Counterparts
[↗ 2542 01](#) [↗ 2542 02](#) [↗ 2542 03](#)
[↗ P 129](#) [↗ P 129 S](#)

Accessories
[↗ 2533 01](#)

25

2542 04

Designation	Pole Number	PU (Pieces)	MDQ (Pieces)
2542 04	8	100	200

Packaging:

individually in plastic bag, in cardboard box