

Accessories

PROTECTIV CAP, SMA, Ohm, jack (female)

62_SMA-0-0-8/--3_-E

Properties

- Easy to work with
- Available for plug(male) and jack(female) connectors



General data	
Technology	Radio Frequency
Weight	0.00274 kg
Body material	Brass / SUCOPLATE (R) Plating
Gasket material	VMQ (Silicone rubber)
Operation temperature	-65 °C ... 165 °C
Remarks	HUBER+SUHNER ECO Ingress protection according to IP68


Accessories

PROTECTIV CAP, SMA, Ohm, jack (female)

62_SMA-0-0-8/--3_-E

Catalogue drawing

Diese Zeichnung ist unser geistiges Eigentum und darf ohne unsere Einwilligung weder kopiert, reproduziert, noch in irgendeiner Weise oder in irgendeiner Weise veröffentlicht, gemacht werden. Diese Zeichnung ist unser geistiges Eigentum und darf ohne unsere schriftliche Genehmigung nicht weitergegeben, kopiert, reproduziert, noch in irgendeiner Weise oder in irgendeiner Weise veröffentlicht, gemacht werden. This drawing is our intellectual property and must not be used for any other purpose than which it was supplied, or be reproduced without written permission of the owners.

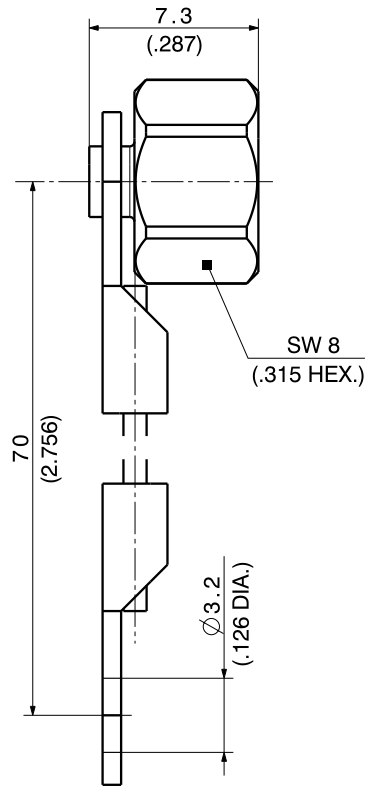

type / Typ: 62_SMA-0-0-8		
⌀ dimensions in millimeter [mm]	part no. / Teile Nr.: PRO-00176271	A sheet/Blatt: XX / XX
description / Beschreibung	Protective cap	Release
	DCA-00176271	A
alternative ID :		

Ordering Information Table

Item number	Item description
84120887	62_SMA-0-0-8/--3_-E

HUBER+SUHNER is certified by ISO 9001, ISO 14001, ISO 45001, IATF 16949, AS/ EN 9100 and ISO/TS 22163-IRIS. Waiver: Facts and figures herein are for information only and do not represent any warranty of any kind. DOCUMENT PIM-P1794 / Date of publication: 09.08.2024 / uncontrolled copy