


USB3.0 A female to B female keystone coupler

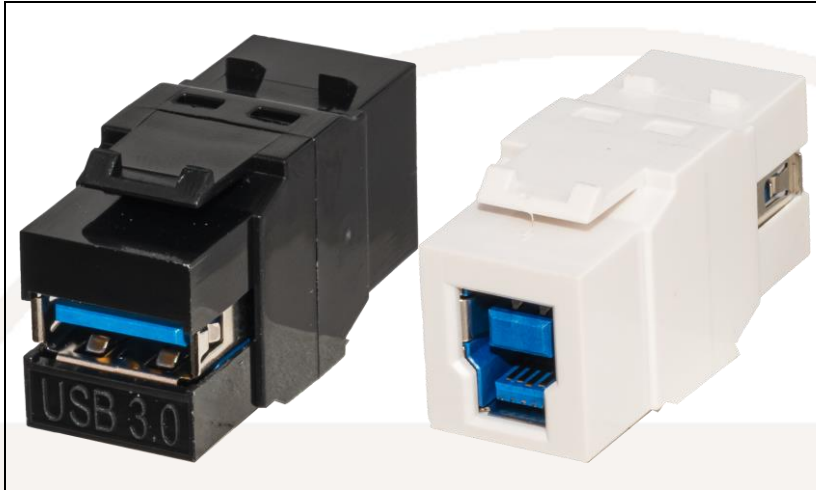

USB3 A to B keystone coupler (KCUAB3Bk/Wh)

This USB3.0 keystone coupler can be used to convert a USB3 A to USB3 B. With its standardised dimensions this adapter can be used for easy snap-in mounting in a keystone patch panel, face plate or surface-mount box.

Features

- USB 3.0 keystone coupler (A female to B female type connectors)
- Allows conversion of USB3 B male into USB3 A female and vice versa
- Reversible coupler easily mounts both ways round in industry standard keystone patch panels
- Supports USBA 1.1 through to USB 3.0 devices
- Connection: USB3.0 A female / B female
- Available in black or white
- Panel mount, low-profile panel mount and D UNIVERSAL versions also available







Specifications

- Dimensions: 40x25x19mm (including primary packaging)
- Weight: 12.1g (including primary packaging)
- Housing: ABS UL94V-0
- Colour: black or white
- Packaging: Supplied in individual polythene bags, then in bags of 20

Product Code	EAN	Dimensions	Weight
KCUAB3Bk	5055386512840	40x25x19mm	12.1g
KCUAB3Wh	5055386512857	40x25x19mm	12.1g
KCUAB3Dpm	5055386512864	70x50x20mm	16g
KCUAB3Bpm	5055386512871	70x50x20mm	16g
KCUAB3pm	5055386512888	70x50x20mm	24g





Commodity Code: 85444920

Country of Origin: China

D UNIVERSAL	Low profile panel mount	Panel mount
		
		
KCUAB3Dpm	KCUAB3Bpm	KCUAB3pm

ROHS Compliant

Code: KCUAB3*
(* Bk/Wh)

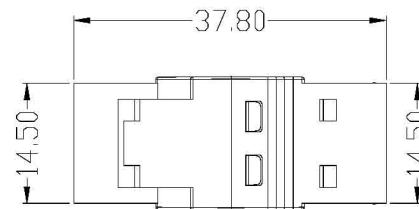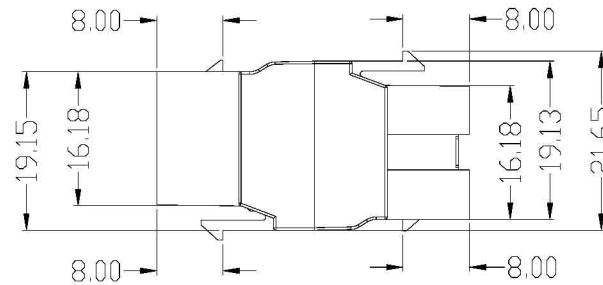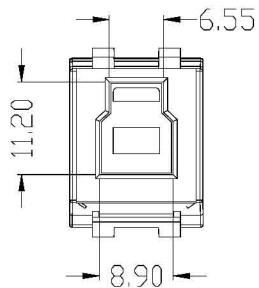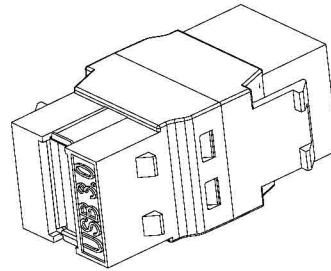

ELECTRICAL

- (1) INSULATION RESISTANCE :20MΩ MIN. at 300V DC.
- (2) CONTACT RESISTANCE : 2Ω MAX.
- (3) DIELECTRIC WITHSTANDING VOLTAGE:1000V AC ,1MIN 0.5mA MAX.

MECHANICAL

- (1) Materials: UV stabilized PC+ABS