



Careers

Home : Connectors : TNC : TC-240-TM-RA-D

TC-240-TM-RA-D

Type TNC, male (plug), right angle, TC style connector for FBT-240, LMR[®]-240, and TCOM[®]-240 type cables. The TC-240-TM-RA-D features a solder-pin connector and is a perfect option for stranded center conductors. The TNC is a miniature, threaded, weatherproof connector with a contact design similar to a BNC series and a higher frequency performance.



Stock Code: 3190-6547

TNC-male (plug) right angle crimp connector, solder-on pin

Inventory Status

Distributor	Qty	Order
Mouser Electronics	707	Buy
DigiKey	34	Buy

Showing 1 to 2 of 2 entries

< 1 >



Specs



Hardware



Documentation



Compatible with



CAD Model



Ask an Expert

Specifications

TC-240-
Part Number **TM-RA-
D**

Max
Frequency **6**
(GHz)

Pin Finish **Gold**

Length (mm) **33.3**

Stock Code **3190-
6547**

VSWR Freq **<1.35:1**

Length (in) **1.31**

Interface **TNC**

VSWR
Frequency **6**
(GHz)

Width (mm) **31.5**

Width (in) **1.24**

Gender **Male
(plug)**

Coupling Nut **Hex/Knurl**

Weight (g) **32.44**

Orientation **Right
Angle**

Inner
Contact **Solder**
Attach

Weight (lb) **0.07**

PIM Rating

Impedance **50**
(ohms)

Outer
Contact **Crimp**
Attach

Body Finish **Alballoy**

Compatible with

[FBT-240](#)

[LMR-240](#)

[LMR-240-DB](#)

[LMR-240-FR](#)

[LMR-240-LLPX](#)


[LMR-240-MA](#)

[LMR-240-PVC](#)

[TCOM-240](#)

[TCOM-240-FR](#)

Tools and Accessories

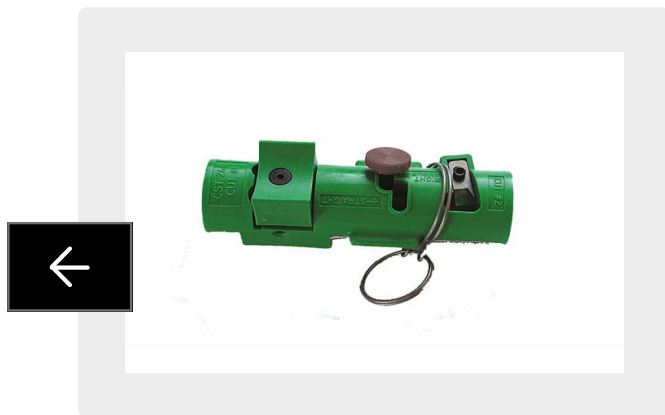

CST-240A



Grounding Kits