


Product Information

13 72 8

KNIPEX WireStripper

KNIPEX WireStripper

American style

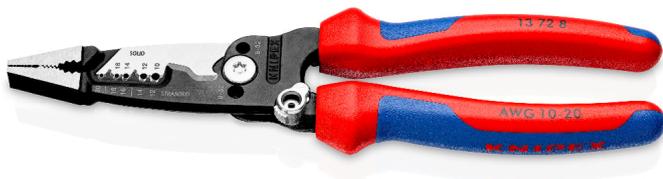

- Strip faster: precise positioning of the wire thanks to location ridges
- Innovative cutting edge geometry, particularly powerful cutting edges: 50% higher cutting capacity and 25% less cutting effort compared to standard wire strippers
- Fast, burr-free cutting of threaded rods and screws of UNC 6-32 and 8-32 up to class 4.6
- Precisely ground: Stripping profiles for conductors from 18-10 AWG(solid) and 20-12 AWG (finely stranded)
- Easy cutting of copper and aluminium cables up to Ø 15 mm (1/2")
- Multifunctional gripping surfaces for reliable gripping, holding and bending of flat and round material as well as for twisting wires
- High stability and good accessibility thanks to hybrid tips on the pliers head, which are flat and wide
- Convenient: comfortable opening width and ergonomic handle shape, integrated opening spring makes frequent cutting easier
- Ideal for right- and left-handed users: locking device can be operated from either side
- Clear-cut outside edges on the jaws for deburring plastic pipes

MM 

General	
Article No.	13 72 8
EAN	4003773086680
pliers	black atramentized
head	polished
handles	with multicomponent handles
Weight	285 g
Dimensions	200 x 55 x 21 mm
REACH compliant	does not contain SVHC
RoHS compliant	not applicable
Technical details	
Cutting capacity copper cable, multiple-stranded	Ø 15 mm
Cutting capacity copper cable, multiple-stranded	50 mm ²
AWG	1 / 0

Technical changes and errors excepted





