

**RoHS  
Compliant**



## Description

These kits contain a variety of O-ring sets categorized by type (Metric or Inch), material (NBR or FKM), number of pieces (ranging from 382 to 419), and hardness rating (70 Shore):

### Metric O-ring Sets:

Made of NBR or FKM materials, available in sizes with 382, 386, 404, 407, or 419 pieces, all rated at 70 Shore hardness.

### Inch O-ring Sets:

Made of NBR material, available in sizes with 382, 407, or 419 pieces, all rated at 70 Shore hardness.

This collection is ideal for various sealing applications requiring precise sizes and material-specific properties.

## MP013942

Comprehensive Metric O-Ring Set (382PC, 70 Shore, NBR) Get the right seal every time with our extensive 382-piece metric O-ring set, featuring high-quality NBR (nitrile butadiene rubber) material with a 70 Shore hardness rating.



## 5A 382PC METRIC SERIES O-RING ASSORTMENT

O-RING SERVICE KIT NATURAL BUNA RUBBER(NBR) METRIC SIZE 70 SHORE

PROFESSIONAL QUALITY 382 PIECES

Part Numbers	Nominal Sizes		Quantity
	I/D	Section	In Kit
As568	2.90	1.78	20
006	3.69	1.78	20
007	4.47	1.78	20

Part Numbers	Nominal Sizes		Quantity
	I/D	Section	In Kit
As568	20.22	3.53	10
211	21.82	3.53	10
212	23.39	3.53	10

## 5A 382PC METRIC SERIES O-RING ASSORTMENT

continue

O-RING SERVICE KIT NATURAL BUNA RUBBER(NBR) METRIC SIZE 70 SHORE

PROFESSIONAL QUALITY 382 PIECES

Part Numbers	Nominal Sizes		Quantity
	I/D	Section	
As568			In Kit
009	5.29	1.78	20
010	6.07	1.78	20
011	7.65	1.78	20
012	9.25	1.78	20
110	9.19	2.62	13
111	10.77	2.62	13
112	12.37	2.62	13
113	13.95	2.62	13
114	15.54	2.62	13
115	17.12	2.62	13
116	18.72	2.62	13
210	18.64	2.62	10

Part Numbers	Nominal Sizes		Quantity
	I/D	Section	
As568			In Kit
214	25.00	3.53	10
215	26.57	3.53	10
216	28.17	3.53	10
217	29.57	3.53	10
218	31.34	3.53	10
219	32.92	3.53	10
220	34.52	3.53	10
221	36.10	3.53	10
222	37.70	3.53	10
325	37.47	5.33	7
326	40.65	5.33	7
327	43.82	5.33	7

Convenient re-sealable plastic case. Weight: 0.65kg

### MP013943

Comprehensive Metric O-Ring Set (382PC, 70 Shore, NBR) Get the right seal every time with our extensive 382-piece metric O-ring set, featuring high-quality NBR (nitrile butadiene rubber) material with a 70 Shore hardness rating.



## 5B 382PC METRIC SERIES O-RING ASSORTMENT

O-RING SERVICE KIT NATURAL BUNA RUBBER(NBR) METRIC SIZE 70 SHORE

PROFESSIONAL QUALITY 382 PIECES

Part Numbers	Nominal Sizes			Quantity
	I/D	O/D	Section	
JIS				In Kit
P3	2.80	6.6	1.9	20
P4	3.80	7.6	1.9	20
P5	4.80	8.6	1.9	18
P6	5.80	9.6	1.9	18
P7	6.80	10.6	1.9	18

Part Numbers	Nominal Sizes			Quantity
	I/D	O/D	Section	
JIS				In Kit
G22	22.0	28.0	3.0	10
P22 4	22.1	29.1	3.5	10
G25	24.4	30.6	3.1	10
P25	24.7	31.7	3.5	10
P26	25.7	32.7	3.5	10

## 5B 382PC METRIC SERIES O-RING ASSORTMENT

continue

O-RING SERVICE KIT NATURAL BUNA RUBBER(NBR) METRIC SIZE 70 SHORE

PROFESSIONAL QUALITY 382 PIECES

Part Numbers	Nominal Sizes			Quantity In Kit
	I/D	O/D	Section	
JIS				
P8	7.80	11.6	1.9	18
P9	8.80	12.6	1.9	18
P10A	9.80	14.6	2.4	13
P11	10.80	15.6	2.4	13
P12	11.80	16.8	2.4	13
P14	13.80	18.6	2.4	13
P16	15.80	20.6	2.4	13
P18	17.80	22.6	2.4	13
P20	19.80	24.6	2.4	13
G20	20.00	26.0	3.0	10

Part Numbers	Nominal Sizes			Quantity In Kit
	I/D	O/D	Section	
JIS				
G30	29.4	35.6	3.1	10
P30	29.7	36.7	3.5	10
P32	31.7	38.7	3.5	10
P34	33.7	40.7	3.5	10
G35	34.4	40.6	3.1	10
P36	35.7	42.7	3.5	10
G40	39.4	45.6	3.1	10
P10	39.7	46.7	3.5	10
G45	44.4	50.6	3.1	11
P48	47.7	54.7	3.5	10

Convenient re-sealable plastic case. Weight: 0.65kg

### MP013944

Expanded Metric O-Ring Set (386PC, 70 Shore, NBR)  
Take your sealing capabilities to the next level with our 386-piece metric O-ring set, featuring high-quality NBR material and a 70 Shore hardness rating for a precise fit and reliable seal.



## 5C 386PC METRIC SERIES O-RING ASSORTMENT

O-RING SERVICE KIT NATURAL BUNA RUBBER(NBR) METRIC SIZE 70 SHORE

PROFESSIONAL QUALITY 386 PIECES

Part Numbers	Nominal Sizes			Quantity In Kit
	I/D	O/D	Section	
As568				
006	3	7	2.0	16
007	4	8	2.0	16
008	5	9	2.0	16
009	6	10	2.0	16
010	7	11	2.0	16
011	8	12	2.0	16

Part Numbers	Nominal Sizes			Quantity In Kit
	I/D	O/D	Section	
As568				
211	20	23	3.0	12
212	22	28	3.0	12
213	24	30	3.0	12
214	25	31	3.0	12
215	27	33	3.0	12
216	28	34	3.0	12

## 5C 386PC METRIC SERIES O-RING ASSORTMENT

continue

O-RING SERVICE KIT NATURAL BUNA RUBBER(N-BR) METRIC SIZE 70 SHORE

PROFESSIONAL QUALITY 386 PIECES

Part Numbers	Nominal Sizes			Quantity
	I/D	O/D	Section	
As568				In Kit
012	10	14	2.0	16
110	10	15	2.5	13
111	11	16	2.5	13
112	12	17	2.5	13
113	14	19	2.5	13
114	16	21	2.5	13
115	1	22	2.5	13
116	19	24	2.5	13
210	19	25	3.0	12

Part Numbers	Nominal Sizes			Quantity
	I/D	O/D	Section	
As568				In Kit
217	30	36	3.0	12
218	32	36	3.0	12
219	33	36	3.0	12
220	35	41	3.0	12
221	36	42	3.0	12
222	38	44	3.0	12
325	38	46	4.0	9
326	41	49	4.0	9
327	42	52	4.0	9

Convenient re-sealable plastic case. Weight: 0.65kg

### MP013945

Comprehensive Metric O-Ring Set (382PC, 70 Shore, NBR) Get the right seal every time with our extensive 382-piece metric O-ring set, featuring high-quality NBR (nitrile butadiene rubber) material with a 70 Shore hardness rating.



## BOX 382PC METRIC SERIES O-RING ASSORTMENT

O-RING SERVICE KIT NATURAL BUNA RUBBER(N-BR) METRIC SIZE 70 SHORE

PROFESSIONAL QUALITY 382 PIECES

Part Numbers	Nominal Sizes		Quantity
	I/D	Section	
As568			In Kit
006	2.90	1.78	20
007	3.69	1.78	20
008	4.47	1.78	20
009	5.29	1.78	20
010	6.07	1.78	20
011	7.65	1.78	20
012	9.25	1.78	20

Part Numbers	Nominal Sizes		Quantity
	I/D	Section	
Dash No.			In Kit
211	20.22	3.53	10
212	21.82	3.53	10
213	23.40	3.53	10
214	24.99	3.53	10
215	26.58	3.53	10
216	28.17	3.53	10
217	29.75	3.53	10

## BOX 382PC METRIC SERIES O-RING ASSORTMENT

continue

O-RING SERVICE KIT NATURAL BUNA RUBBER(N-BR) METRIC SIZE 70 SHORE

PROFESSIONAL QUALITY 382 PIECES

Part Numbers	Nominal Sizes		Quantity
	I/D	Section	
As568			In Kit
110	9.19	2.62	13
111	10.78	2.62	13
112	12.31	2.62	13
113	13.95	2.62	13
114	15.54	2.62	13
115	17.13	2.62	13
116	18.72	2.62	13
210	18.64	3.53	10

Part Numbers	Nominal Sizes		Quantity
	I/D	Section	
Dash No.			In Kit
218	31.34	3.53	10
219	32.92	3.53	10
220	34.52	3.53	10
221	36.10	3.53	10
222	37.69	3.53	10
325	37.47	5.33	7
326	40.65	5.33	7
327	43.82	5.33	7

Convenient re-sealable plastic case. Weight: 0.65kg

### MP013946

Comprehensive Inch O-Ring Set (382PC, 70 Shore, NBR)  
Get the right seal every time with our extensive 382-piece inch O-ring set, featuring high-quality NBR (nitrile butadiene rubber) material with a 70 Shore hardness rating, designed for imperial measurements.



## 382PC INCH SERIES O-RING ASSORTMENT

O-RING SERVICE KIT NATURAL BUNA RUBBER(N-BR) INCH SIZE 70 SHORE

PROFESSIONAL QUALITY 382 PIECES

Location	Actual size			Quantity
	I/D	O/D	Section	
				In Kit
006	1/8	1/4	1/16	20
007	5/32	9/32	1/16	20
008	3/16	5/16	1/16	20
009	7/32	11/32	1/16	20
010	1/4	3/8	1/16	20
011	5/16	7/16	1/16	20
012	3/8	1/2	1/16	20
110	3/8	9/16	3/32	13
111	7/16	5/8	3/32	13

Location	Actual size			Quantity
	I/D	O/D	Section	
				In Kit
R16	13/16	1-1/16	1/8	10
R17	7/8	1-1/8	1/8	10
R18	15/16	1-3/16	1/8	10
R19	1	1-1/4	1/8	10
R20	1-1/16	1-5/16	1/8	10
R21	1-1/8	1-3/8	1/8	10
R22	1-3/16	1-7/16	1/8	10
R23	1-1/4	1-1/2	1/8	10
R24	1-5/16	1-9/16	1/8	10



## 382PC INCH SERIES O-RING ASSORTMENT

continue

O-RING SERVICE KIT NATURAL BUNA RUBBER(N-BR) INCH SIZE 70 SHORE

PROFESSIONAL QUALITY 382 PIECES

Location	Actual size			Quantity In Kit
	I/D	O/D	Section	
112	1/2	11/16	3/32	13
113	9/16	3/4	3/32	13
114	5/8	13/16	3/32	13
115	11/16	7/8	3/32	13
116	3/4	15/16	3/32	13
210	3/4	1	1/8	12

Location	Actual size			Quantity In Kit
	I/D	O/D	Section	
R25	1-3/8	1-5/8	1/8	10
R26	1-7/16	1-11/16	1/8	10
R27	1-1/2	1-3/4	1/8	10
R28	1-1/2	1-7/8	3/16	7
R29	1-5/8	2	3/16	7
R30	1-3/4	2-1/8	3/16	7

Convenient re-sealable plastic case. Weight: 0.65kg

### MP013947

Ultimate Metric O-Ring Set (404PC, 70 Shore, NBR)  
Experience the ultimate in sealing solutions with our 404-piece metric O-ring set, featuring high-quality NBR material and a 70 Shore hardness rating for a wide range of applications.



## BOX 404PC METRIC O-RING ASSORTMENT

O-RING SERVICE KIT NATURAL BUNA RUBBER(N-BR) METRIC SIZE 70 SHORE

PROFESSIONAL QUALITY 404 PIECES

Numbers On Kit	Nominal Sizes		Quantity InKit
	I/D	Section	
R-01	3	2	18
R-02	4	2	18
R-03	5	2	18
R-04	6	2	18
R-05	7	2	17
R-06	8	2	17
R-07	10	2	17
R-08	10	2.5	14
R-09	11	2.5	14
R-10	12	2.5	14

Numbers On Kit	Sizes		Quantity InKit
	I/D	Section	
R-16	20	3	12
R-17	22	3	12
R-18	24	3	12
R-19	25	3	12
R-20	27	3	12
R-21	28	3	12
R-22	30	3	12
R-23	32	3	12
R-24	33	3	12
R-25	35	3	12

## BOX 404PC METRIC O-RING ASSORTMENT

continue

O-RING SERVICE KIT NATURAL BUNA RUBBER(N-BR) METRIC SIZE 70 SHORE

PROFESSIONAL QUALITY 404 PIECES


Numbers	Nominal Sizes		Quantity
	I/D	Section	
On Kit	I/D	Section	InKit
R-11	14	2.5	14
R-12	16	2.5	14
R-13	17	2.5	14
R-14	19	2.5	14
R-15	19	3	12

Numbers	Sizes		Quantity
	I/D	Section	
On Kit	I/D	Section	InKit
R-26	36	3	12
R-27	38	3	12
R-28	38	4	9
R-29	42	4	9
R-30	45	4	9

Convenient re-sealable plastic case. Weight: 0.65kg

### MP013948

Premium Metric O-Ring Set (407PC, 70 Shore, NBR)  
Upgrade your sealing capabilities with our 407-piece metric O-ring set, featuring high-quality NBR material and a 70 Shore hardness rating for a precise fit and reliable seal.

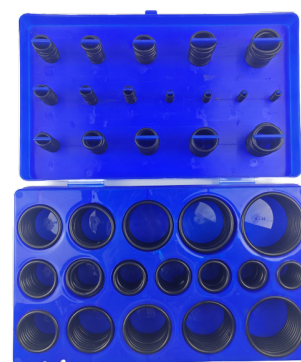

## 8B 407PC METRIC SERIES O-RING ASSORTMENT

O-RING SERVICE KIT NATURAL BUNA RUBBER(N-BR) METRIC SIZE 70 SHORE

PROFESSIONAL QUALITY 407 PIECES

Part Numbers	Nominal Sizes		Quantity
	I/D	Section	
As568	I/D	Section	In Kit
06	2.90	1.78	20
08	4.48	1.78	20
010	6.07	1.78	20
011	7.66	1.78	20
012	9.25	1.78	20
014	12.42	1.78	20
110	9.19	2.62	13
111	10.77	2.62	13
112	12.37	2.62	13
113	13.98	2.62	13
114	15.54	2.62	13

Part Numbers	Nominal Sizes		Quantity
	I/D	Section	
As568	I/D	Section	In Kit
211	20.22	3.53	10
212	21.82	3.53	10
213	23.40	3.53	10
214	25.00	3.53	10
215	26.57	3.53	10
216	28.17	3.53	10
217	29.57	3.53	10
218	31.34	3.53	10
219	32.92	3.53	10
220	34.52	3.53	10
221	36.10	3.53	10

## 8B 407PC METRIC SERIES O-RING ASSORTMENT

continue

O-RING SERVICE KIT NATURAL BUNA RUBBER(NBR) METRIC SIZE 70 SHORE

PROFESSIONAL QUALITY 407 PIECES

Part Numbers	Nominal Sizes		Quantity
	I/D	Section	In Kit
As568	17.13	2.62	13
115	18.72	2.62	13
116	20.29	2.62	13
117	21.89	2.62	13
118	18.64	3.53	10

Part Numbers	Nominal Sizes		Quantity
	I/D	Section	In Kit
As568	37.70	3.53	10
222	40.87	3.53	10
223	44.04	3.53	10
224	47.22	3.53	10
225	50.40	3.53	10

Convenient re-sealable plastic case. Weight: 0.65kg

### MP013949

Deluxe Metric O-Ring Set (419PC, 70 Shore, NBR) Get the most comprehensive sealing solution with our 419-piece metric O-ring set, featuring high-quality NBR material and a 70 Shore hardness rating for a wide range of applications.



## 8C 419PC METRIC SERIES O-RING ASSORTMENT

O-RING SERVICE KIT NATURAL BUNA RUBBER(NBR) METRIC SIZE 70 SHORE

PROFESSIONAL QUALITY 419 PIECES

Numbers	Nominal Sizes		Quantity
	I/D	Section	In Kit
On Kit	3	1.5	20
R-01	4.4	2	20
R-02	5	2	18
R-03	7	1.5	23
R-04	10	1.5	23
R-05	13	2.5	23
R-06	10	2.5	14
R-07	11	2.5	13
R-08	13	2.5	14
R-09	14	2.5	13

Numbers	Nominal Sizes		Quantity
	I/D	Section	In Kit
As568	20	3.5	10
R-17	22	3.5	10
R-18	23.5	3.5	10
R-19	25	3.5	10
R-20	26.5	3.5	10
R-21	28	3.5	10
R-22	30	3.5	10
R-23	31	3.5	10
R-24	33	3.5	10
R-25	34.5	3.5	10



## 8C 419PC METRIC SERIES O-RING ASSORTMENT

continue

O-RING SERVICE KIT NATURAL BUNA RUBBER(NBR) METRIC SIZE 70 SHORE

PROFESSIONAL QUALITY 419 PIECES

Numbers	Nominal Sizes		Quantity
	I/D	Section	
On Kit			In Kit
R-11	16	2.5	14
R-12	18	2.5	14
R-13	19	2.5	13
R-14	21	2.5	14
R-15	22	2.5	13
R-16	18	3.5	10

Numbers	Nominal Sizes		Quantity
	I/D	Section	
As568			In Kit
R-27	36	3.5	10
R-28	38	3.5	10
R-29	41	3.5	10
R-30	44	3.5	10
R-31	47	3.5	10
R-32	50	3.5	10

Convenient re-sealable plastic case. Weight: 0.65kg

### MP013950

Deluxe Inch O-Ring Set (419PC, 70 Shore, NBR) Get the most comprehensive sealing solution with our 419-piece inch O-ring set, featuring high-quality NBR material and a 70 Shore hardness rating, designed for imperial measurements



## 419PC INCH SERIES O-RING ASSORTMENT

O-RING SERVICE KIT NATURAL BUNA RUBBER(NBR) INCH SIZE 70 SHORE

PROFESSIONAL QUALITY 419 PIECES

Part Number	Nominal Sizes			Quantity
	I/D	O/D	Section	
On Kit				In Kit
R-01	1/8	1/4	1/16	20
R-02	3/16	5/16	1/16	20
R-03	1/4	3/8	1/16	18
R-04	5/16	7/16	1/16	23
R-05	3/8	1/2	1/16	23
R-06	1/2	5/8	1/16	23
R-07	3/8	9/16	3/32	14
R-08	7/16	5/8	3/32	13
R-09	1/2	11/16	3/32	14
R-10	9/16	3/4	3/32	13
R-11	5/8	13/16	3/32	14

Part Number	Nominal Sizes			Quantity
	I/D	O/D	Section	
On Kit				In Kit
R17	13/16	11/16	1/8	10
R18	7/8	11/8	1/8	10
R19	15/16	13/16	1/8	10
R20	1	11/4	1/8	10
R21	11/16	15/16	1/8	10
R22	11/8	13/8	1/8	10
R23	13/16	17/6	1/8	10
R24	11/4	11/2	1/8	10
R25	15/16	19/16	1/8	10
R26	13/8	15/8	1/8	10
R27	17/16	111/16	1/8	10

## 419PC INCH SERIES O-RING ASSORTMENT

continue

O-RING SERVICE KIT NATURAL BUNA RUBBER(NBR) INCH SIZE 70 SHORE

PROFESSIONAL QUALITY 419 PIECES

Part Number	Nominal Sizes			Quantity
	I/D	O/D	Section	
On Kit	I/D	O/D	Section	In Kit
R-12	11/16	7/8	3/32	14
R-13	3/4	15/16	3/32	13
R-14	13/16	1	3/32	14
R-15	7/8	1-1/16	3/32	13
R-16	3/4	1	1/8	10

Part Number	Nominal Sizes			Quantity
	I/D	O/D	Section	
On Kit	I/D	O/D	Section	In Kit
R28	11/2	13/4	1/8	10
R29	15/8	17/8	1/8	10
R-30	13/4	2	1/8	10
R-31	17/8	21/8	1/8	10
R-32	3/4	21/4	1/8	10

Convenient re-sealable plastic case. Weight: 0.65kg

### MP013951

Premium Inch O-Ring Set (407PC, 70 Shore, NBR) Upgrade your sealing capabilities with our 407-piece inch O-ring set, featuring high-quality NBR material and a 70 Shore hardness rating, designed for imperial measurements.



## 407PC INCH SERIES O-RING ASSORTMENT

O-RING SERVICE KIT NATURAL BUNA RUBBER(NBR) INCH SIZE 70 SHORE

PROFESSIONAL QUALITY 407 PIECES

Part Number	Nominal Sizes			Quantity
	I/D	O/D	Section	
On Kit	I/D	O/D	Section	In Kit
R-01	1/8	1/4	1/16	20
R-02	3/16	5/16	1/16	20
R-03	1/4	3/8	1/16	18
R-04	5/16	7/16	1/16	23
R-05	3/8	1/2	1/16	23
R-06	1/2	5/8	1/16	23
R-07	3/8	9/16	3/32	14
R-08	7/16	5/8	3/32	13
R-09	1/2	11/16	3/32	14
R-10	9/16	3/4	3/32	13

Part Number	Nominal Sizes			Quantity
	I/D	O/D	Section	
On Kit	I/D	O/D	Section	In Kit
R17	13/16	1-1/16	1/8	10
R18	7/8	1-1/8	1/8	10
R19	15/16	1-3/16	1/8	10
R20	1	1-1/4	1/8	10
R21	1-1/16	1-5/16	1/8	10
R22	11/8	1-3/8	1/8	10
R23	1-3/16	1-7/16	1/8	10
R24	1-1/4	1-1/2	1/8	10
R25	1-5/16	1-9/16	1/8	10
R26	1-3/8	1-5/8	1/8	10

## 407PC INCH SERIES O-RING ASSORTMENT

continue

O-RING SERVICE KIT NATURAL BUNA RUBBER(N-BR) INCH SIZE 70 SHORE

PROFESSIONAL QUALITY 407 PIECES

Part Number	Nominal Sizes			Quantity
	I/D	O/D	Section	
On Kit				In Kit
R-11	5/8	13/16	3/32	14
R-12	11/16	7/8	3/32	14
R-13	3/4	15/16	3/32	13
R-14	13/16	1	3/32	14
R-15	7/8	1-1/16	3/32	13
R-16	3/4	1	1/8	10

Part Number	Nominal Sizes			Quantity
	I/D	O/D	Section	
On Kit				In Kit
R27	1-7/16	1-11/16	1/8	10
R28	1-1/2	1-3/4	1/8	10
R29	1-5/8	1-7/8	1/8	10
R-30	1-3/4	2	1/8	10
R-31	1-7/8	2-1/8	1/8	10
R-32	3/4	2-1/4	1/8	10

Convenient re-sealable plastic case. Weight: 0.65kg

### MP013952

High-Temperature Metric O-Ring Set (419PC, 70 Shore, FKM) Experience high-temperature sealing performance with our 419-piece metric O-ring set, featuring high-quality FKM (fluorocarbon) material and a 70 Shore hardness rating, designed for extreme applications.



## 8C 419PC METRIC VITON O-RING ASSORTMENT

O-RING SERVICE KIT VITON (FKM) METRIC SIZE 70 SHORE

PROFESSIONAL QUALITY 419 PIECES

Numbers	Nominal Sizes		Quantity
	I/D	Section	
On Kit			In Kit
R-01	3	1.5	20
R-02	4.4	2	20
R-03	5	2	18
R-04	7	1.5	23
R-05	10	1.5	23
R-06	13	2.5	23
R-07	10	2.5	14
R-08	11	2.5	13
R-09	13	2.5	14

Numbers	Nominal Sizes		Quantity
	I/D	Section	
As568			In Kit
R-17	20	3.5	10
R-18	22	3.5	10
R-19	23.5	3.5	10
R-20	25	3.5	10
R-21	26.5	3.5	10
R-22	28	3.5	10
R-23	30	3.5	10
R-24	31	3.5	10
R-25	33	3.5	10

## 8C 419PC METRIC VITON O-RING ASSORTMENT

continue

O-RING SERVICE KIT VITON (FKM) METRIC SIZE 70 SHORE PROFESSIONAL QUALITY 419 PIECES

Numbers	Nominal Sizes		Quantity
On Kit	I/D	Section	In Kit
R-10	14	2.5	13
R-11	16	2.5	14
R-12	18	2.5	14
R-13	19	2.5	13
R-14	21	2.5	14
R-15	22	2.5	13
R-16	18	3.5	10

Numbers	Nominal Sizes		Quantity
As568	I/D	Section	In Kit
R-26	34.5	3.5	10
R-27	36	3.5	10
R-28	38	3.5	10
R-29	41	3.5	10
R-30	44	3.5	10
R-31	47	3.5	10
R-32	50	3.5	10

Convenient re-sealable plastic case. Weight: 0.65kg

### Part Number Table

Description	Part Number
METRIC O-RING SET, NBR, 382PC, 70 SHORE	MP013942
METRIC O-RING SET, NBR, 382PC, 70 SHORE	MP013943
METRIC O-RING SET, NBR, 386PC, 70 SHORE	MP013944
METRIC O-RING SET, NBR, 382PC, 70 SHORE	MP013945
INCH O-RING SET, NBR, 382PC, 70 SHORE	MP013946
METRIC O-RING SET, NBR, 404PC, 70 SHORE	MP013947
METRIC O-RING SET, NBR, 407PC, 70 SHORE	MP013948
METRIC O-RING SET, NBR, 419PC, 70 SHORE	MP013949
INCH O-RING SET, NBR, 419PC, 70 SHORE	MP013950
INCH O-RING SET, NBR, 407PC, 70 SHORE	MP013951
METRIC O-RING SET, FKM, 419PC, 70 SHORE	MP013952

**Important Notice :** This data sheet and its contents (the "Information") belong to the members of the AVNET group of companies (the "Group") or are licensed to it. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but the Group assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where the Group was aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict the Group's liability for death or personal injury resulting from its negligence. Multicomp Pro is the registered trademark of Premier Farnell Limited 2019.