

Category 5e Shielded Keystone Panel Mount Coupler



Category 5e Shielded Keystone Panel Mount Coupler (FACK2S)

Features

- Designed to fit industry standard keystone outlets, wall plates and patch panels
- High performance data throughput, meets Category 5e data transfer rates
- Unshielded versions available
- Plug insertion life ≥ 750 times
- Operating temperature: $-40^{\circ}\text{C} \sim +66^{\circ}\text{C}$
- Available as part of our innovative Panel Mount and D UNIVERSAL ranges

Packaging:

- Standard product is supplied in individual polythene bags then in bags of 20. To save time for panel assemblers, FACK2S-24 is available as a “bulk-pack” of 24 pieces without individual bags.

Specifications

- Materials
 - Housing: Nickel plated zinc alloy
 - Contacts: Phosphor bronze, $50\mu\text{m}/1.27\mu\text{m}$ gold plated over contact area
 - Earthing lug material: Stainless steel SUS304
- Colour: Silver
- Dimensions:
 - FACK2S:** 29.7 x 17 x 22.13 mm (LxWxH)
 - FACK2S-24:** 280 x 70 x 35 mm (LxWxH)
- Weight:
 - FACK2S:** 17g
 - FACK2S-24:** 420g approx.





EAN: FACK2S – 5055386505606 FACK2S-24 - 5055386505521

Commodity Code: 85444920

Country of Origin: China

ROHS Compliant

Code: FACK2S

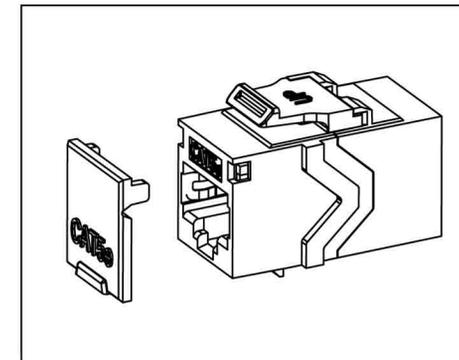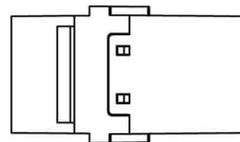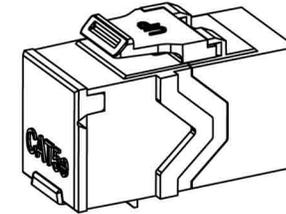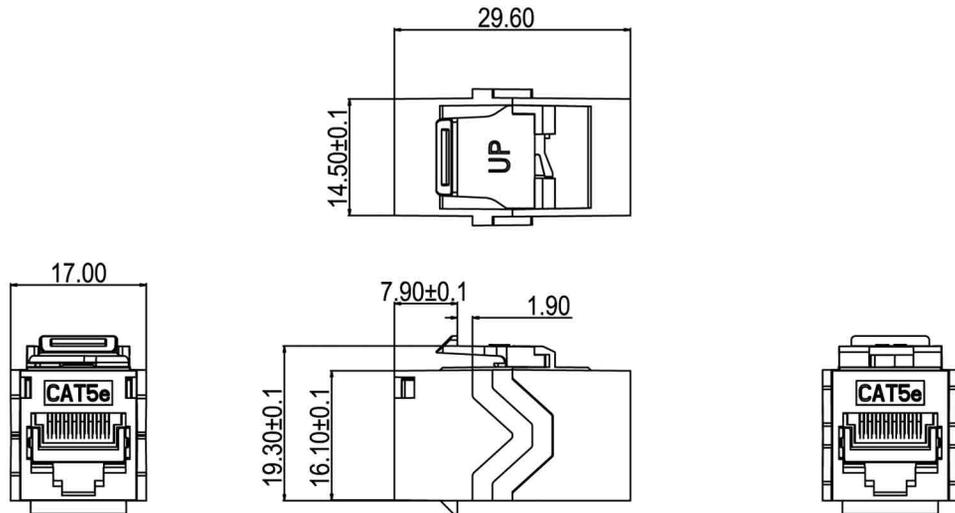

ELECTRICAL:

Current Rating : 1.5A
 Dielectric Withstanding Voltage : 1000V/AC 60Hz
 Insulation Resistance : 500 MΩ MIN.
 Contact Resistance : 20 mΩ MAX.

MECHANICAL:

Durability:RJ45 With 750 Mating Cycles
 and RJ11 With 200 Mating Cycles
 Supporting Cable Diameter: 6~9mm
 Operating Temperature:-10°C to +60°C
 Storage Temperature:-40°C to +70°C

MATERIAL:

Dust cap: PP
 Ground Lug: SUS304
 Front cover: Zn alloy + Nickel Plated
 LATCH: PC 94VO
 Bottom cover: Zn alloy + Nickel Plated