



Connectors > Power Connectors > Circular Power > Circular Power Connectors



Number of Positions: 4

Connector Product Type: **Housing**

Operating Voltage: **600 VDC**

Connector System: **Wire-to-Wire**

Sealable: **No**

Features

Product Type Features

Connector Product Type	Housing
Connector System	Wire-to-Wire
Sealable	No
Connector & Contact Terminates To	Wire & Cable
Connector & Housing Type	Receptacle
Circular Connector Shell Type	All Plastic

Configuration Features

Reverse Numbering	Without
Number of Positions	4
Number of Power Positions	0
Number of Signal Positions	4

Electrical Characteristics

Operating Voltage	600 VAC
-------------------	---------

Contact Features



Reverse Gender	Yes
Contact Type	Socket
Contact Protection	With

Mechanical Attachment

Mating Retention Type	Threaded Coupling
Thread Size	5/8-24 UNEF-2A
Polarization Code	A
Panel Mount Feature Type	Flange with Mounting Holes
Mating Alignment Type	Keyed
Mating Alignment	With
Connector Mounting Type	Panel Mount
Mating Retention	With
Panel Mount Feature	With

Housing Features

Body Orientation	Straight
Housing Color	Black
Housing Material	Nylon
Circular Connector Shell Size	11

Usage Conditions

Operating Temperature Range	-55 – 105 °C[-67 – 221 °F]
Fluid Resistance	None

Operation/Application

Circuit Application	Power & Signal
Shielded	No

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Packaging Features

Packaging Quantity	1
Packaging Method	Package

Product Compliance

For compliance documentation, visit the product page on TE.com>



EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	BFR/CFR/PVC Free, but Br/Cl >900 ppm in other sources.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 2386906-3
LUG CONN CA,REV,SER 1,SZ 11-4,
LGTH 2.0 M



TE Part # 207490-1
CABLE GRIPPER, SIZE 11



TE Part # 796379-2
R/A STRN RELIEF KIT,SZ 11,CPC



TE Part # 1546347-2
R/A CABLE CLAMP KIT,SZ 11,CPC




TE Part # 206429-1
CPC PLUG ASSY, 11-4, REV SEX



TE Part # 213811-1
COUPLING RING,SZ 11,CPC




TE Part # 207489-1
FLEXIBLE CABLE BOOT, SIZE 11

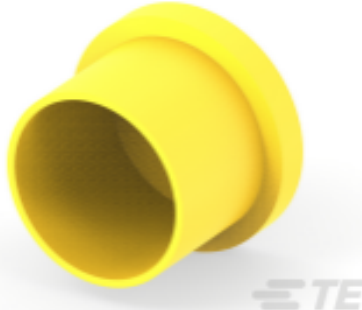

TE Part # 1-2407269-4
CAP, CPC, SIZE 11 RECP & 13 PLUG,
YELLOW



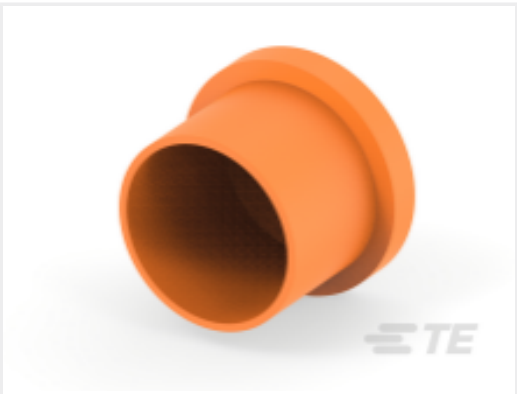


TE Part # 1-2407269-1
CAP, CPC, SIZE 11 RECP & 13 PLUG, ORANGE



TE Part # 1-206062-4
CABLE CLAMP KIT #11



TE Part # 206358-6
CABLE CLAMP KIT, BULK PKG

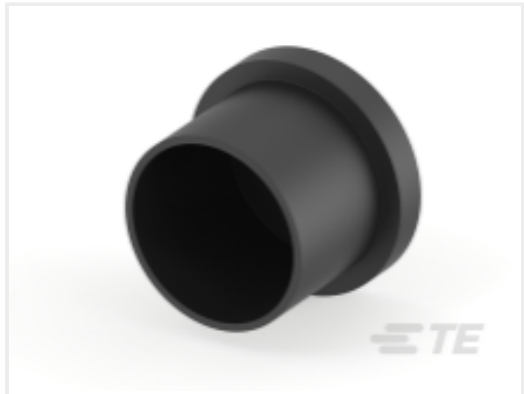

TE Part # 1-2407269-2
CAP, CPC, SIZE 11 RECP & 13 PLUG, BLACK



TE Part # 2386906-1
LUG CONN CA,REV,SER 1,SZ 11-4, LGTH 0.5 M



TE Part # 207299-1
PLUG MTG. FLANGE NO 11 CPC



TE Part # 1-206062-7
CABLE CLAMP KIT, BULK PKG



TE Part # 1-2407269-3
CAP, CPC, SIZE 11 RECP & 13 PLUG, RED



TE Part # 2386906-2
LUG CONN CA,REV,SER 1,SZ 11-4, LGTH 1.0 M



TE Part # 206358-5
CABLE CLAMP ASY, SIZE 11

Also in the Series | AMP CPC



Circular Connector Backshells & Clamps(1)



Circular Power Connectors(211)




Connector Contacts(260)



Connector Hardware(12)



Power Contacts(260)

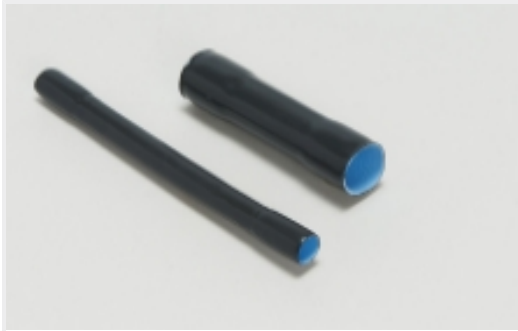

Sealing Sleeves(2)

Also in the Series | CPC Series 1



Circular Power Connectors(211)



Connector Contacts(260)



Power Contacts(260)

Customers Also Bought



TE Part #206429-1
CPC PLUG ASSY, 11-4, REV SEX




TE Part #206708-1
CPC PLUG ASSEMBLY SIZE 13-9




TE Part #211768-1
CPC PLUG ASSEMBLY SIZE 17-9



TE Part #1-206062-4
CABLE CLAMP KIT #11

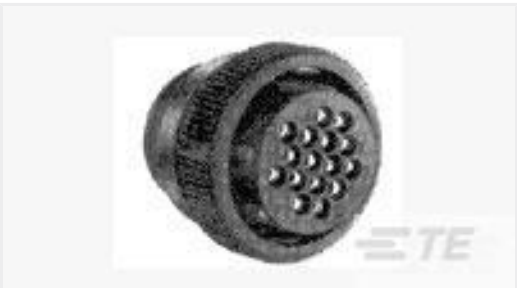

TE Part #206060-1
CPC PLUG ASSEMBLY SIZE 11-4

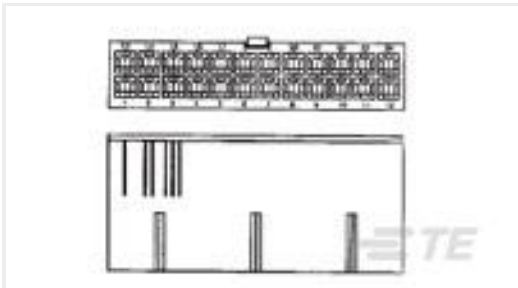

TE Part #2-1586017-4
24P FH PLUG VAL-U-LOK V0



TE Part #1-206062-6
CABLE CLAMP KIT #11



TE Part #206966-7
CABLE SHELL CLAMP SIZE 13



TE Part #206070-8
CABLE CLAMP KIT #17



TE Part #206061-1
RECPT, SZ 11-4, CPC

Documents

Product Drawings
RECPT, SZ 11-4, CPC
English

CAD Files
3D PDF
3D
Customer View Model
ENG_CVM_CVM_206430-1_AC.2d_dxf.zip



English

Customer View Model

[ENG_CVM_CVM_206430-1_AC.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_206430-1_AC.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[AMP Circular Connectors for Commercial Signal & Power Applications](#)

English

Product Specifications

[Application Specification](#)

English

Instruction Sheets

[Instruction Sheet \(U.S.\)](#)

English

Agency Approvals

[UL Report](#)

English