



RoHS Compliant

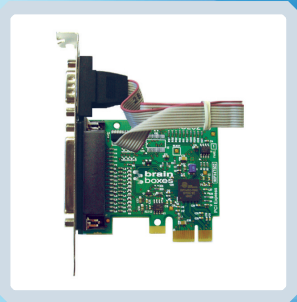

PX-475

PCIe 1xLPT + 1xRS232 1MBaud

"SERIAL CARDS ENGINEERED TO EXCEED EXPECTATIONS"

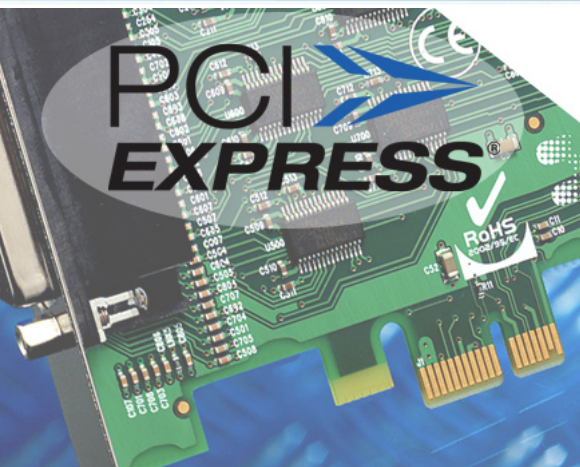

Description

PCI Express Card providing one RS232 serial port and one LPT. Up to 921,600 data transfer rates and the 256 byte deep transmit and 256 byte receive FIFOs, coupled with 1Mbit/s line drivers deliver uncompromising performance on your laptop/PC.

PCI Express is the latest standard in PC connectivity.

With Brainboxes industry renowned Lifetime Warranty and Lifetime Support!

Features

- 1xLPT + 1xRS232
- PCI Express x1, x4, x8 & x16 lane slots socket size
- 256 Byte Tx and 256 Byte Rx FIFOs
- Up to 921,600 Baud
- DB9 connector (9 Pin Male)
- Drivers for all popular operating systems
- Sample Programs, Test & Terminal software
- Lifetime Support
- Lifetime Warranty (registration required)

Software


Microsoft signed drivers (easy installation & robust operation) for:

- Windows Server 2008 32 bit & 64 bit Editions
- Windows Vista 32 bit & 64 bit Editions
- Windows XP 32 bit & 64 bit Editions
- Windows Server 2003 32 bit & 64 bit Editions




As well as: full product documentation, a thorough troubleshooting guide and terminal software. Detailed sample source code for many popular programming languages. Further OS support on next page.

Options

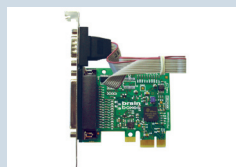


PX-475:
PCIe 1xLPT + 1xRS232
1MBaud

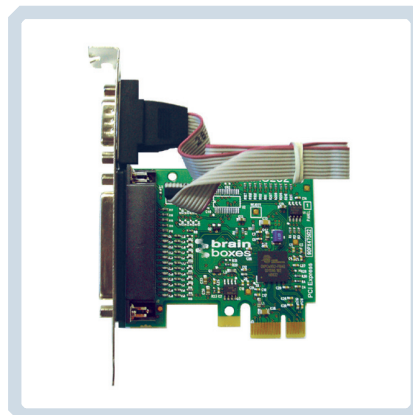

ORDER


 


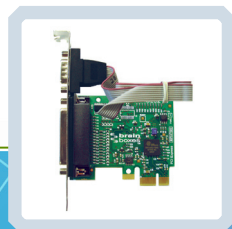


Description
PCIe 1xLPT + 1xRS232 1MBaud

Code
PX-475

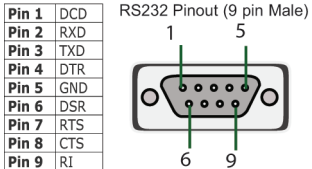

PCIe 1xLPT + 1xRS232 1MBaud

PX-475: Full Specification

Port 	Ports Connector FIFO size Operating Distance Cable	1xLPT + 1xRS232 DB9 connector (9 Pin Male) 256 Tx, 256 Rx EIA - RS232 Standard Not Supplied
Port Settings 	Baud Rate Data Bits Parity Stop Bits Flow Control Tx/Rx Modes	Up to 921,600 5,6,7 or 8 Odd, Even, None, Mark or Space 1, 1.5 or 2 RTS/CTS DSR/DTR XON/XOFF Point to Point
Interface 	OS Compatibility BUS	Windows Vista 32 bit and 64 bit Editions Windows Server 2008 32 bit and 64 bit Editions Windows Server 2003 32 bit and 64 bit Editions Windows XP 32 bit and 64 bit Editions Windows 2000 PCI Express x1, x4, x8 & x16 lane slots
Approvals 	Other Approvals Microsoft Approvals	EMC: CE RoHS WEE Microsoft Certified Gold Partner Windows Vista 32 bit and 64 bit Windows XP 32 bit & 64 bit Windows Server 2008 32 bit and 64 bit Windows Server 2003
General	PCB Layers Power Consumption Weight Size	4 380mA @ 3.3V, 15mA @ 12V 0.060Kg 78mm x 120mm x 20mm
Packing	Box Content Card	Installation CD including manual, Microsoft signed drivers & utilities PCIe 1xLPT + 1xRS232
Product Support 	Warranty Support	Lifetime (online registration required) Lifetime Web, Email and Phone Support from fully qualified, friendly staff who work in and alongside the Product Development Team
Additional  	OEM option Made In Customisable	Available for bulk buy OEM Manufactured in the UK by Brainboxes Winner 2005 European Electronics Industry Awards "Manufacturer of the Year" Brainboxes operate a "Perfect Fit Custom Design" policy for volume users. More Info: sales@brainboxes.com