




## TY Self Adhesive Cable Tie Mounts

### Features and Benefits


TY mounts are particularly suitable for applications with minimal space - they are mounted into the equipment prior to cable installation. The cables can be attached using a range of standard cable ties.

### Application

These products are designed for simple, yet robust, installation in a wide variety of applications - particularly used in telecoms equipment, switchgear and control cabinets.

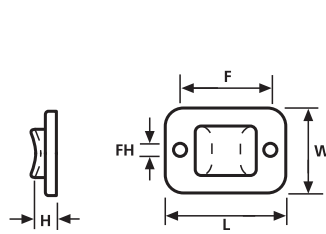

Cable Tie Mounts TY3G1 (S)

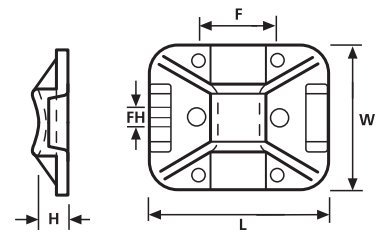

Cable Tie Mounts TY8G1 (S)

#### Material Data

Material	<b>Polyamide 6.6 UV Resistant (PA66W)</b>
Operating Temperature	<b>-40 °C to +85 °C Continuous, (+105 °C for 500 h)</b>
Flammability	<b>UL94 V2 (excluding adhesive)</b>



For more information on the types of adhesive used please turn to page 120.

#### Material Data

Material	<b>Polyamide 6.6 (PA66)</b>
Operating Temperature	<b>-40 °C to +85 °C Continuous, (+105 °C for 500 h)</b>
Flammability	<b>UL94 V2</b>



#### Technical Table

Article-No.	Type	Length (L)	Width (W)	Height (H)	Fixing Hole Ø (FH)	Fixing Hole Centres (F)	Strap Width max. (G)	Material	Colour	Adhesive
151-21319	<b>TY3G1</b>	20.0	14.0	3.7	2.2	15.0	4.0	PA66	Natural (NA)	-
151-11319	<b>TY3G1S</b>	20.0	14.0	3.7	2.2	15.0	4.0	PA66	Natural (NA)	Acrylate
151-11310	<b>TY3G1S</b>	20.0	14.0	3.7	2.2	15.0	4.0	PA66W	Black (BK)	Acrylate
151-21819	<b>TY8G1</b>	32.0	25.0	5.2	3.2	15.0	8.0	PA66	Natural (NA)	-
151-11819	<b>TY8G1S</b>	32.0	25.0	5.2	3.2	15.0	8.0	PA66	Natural (NA)	Acrylate
151-11810	<b>TY8G1S</b>	32.0	25.0	5.2	3.2	15.0	8.0	PA66W	Black (BK)	Acrylate

All dimensions in mm. Subject to technical changes.