


**Sensor, Thermocouple, Type K, Mineral Insulated, Standard Plug
1.5mm, 3.0mm & 6.0mm Diameter**

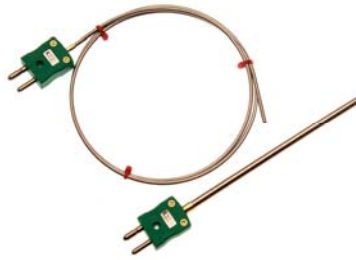

- Type K mineral insulated thermocouples
- Particularly suitable for high pressure, high vacuum or high vibration applications
- Max temperature of probe 1100°C (K) (Plug 220 °C)
- Stainless steel (310) Sheath
- Very flexible
- Direct connection to a Standard Type 'K' Socket

Dimensions		Farnell code	LAB code	Lab Data Ref	Lab Stock Code
Probe Dia	Probe Length				
mm	mm				
1.5	500	TBA	MB-ISK-S15-500-SP	FAR53/A	XF-427-D
1.5	1000	TBA	MB-ISK-S15-1000-SP	FAR53/B	XF-428-D
1.5	2000	TBA	MB-ISK-S15-2000-SP	FAR53/C	XF-429-D
3.0	500	TBA	MB-ISK-S30-500-SP	FAR53/D	XF-430-D
3.0	1000	TBA	MB-ISK-S30-1000-SP	FAR53/E	XF-431-D
3.0	2000	TBA	MB-ISK-S30-2000-SP	FAR53/F	XF-432-D
6.0	500	TBA	MB-ISK-S60-500-SP	FAR53/G	XF-433-D

Data Ref: FAR 53