









## UMK

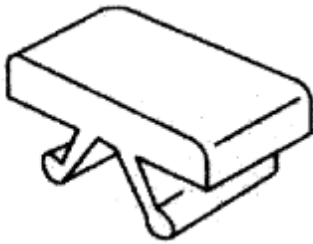

"...8"

Description	Type	Order No.	Pcs. Pkt.
<b>Universal module</b> , comprising: <b>Side element</b> , 11.25 mm wide, with marker groove	 UMK-SE 11,25	<a href="#">29 70 00 2</a>	10
<b>Side element</b> , 11.25 mm wide, without marker groove	 UMK-SE 11,25-1	<a href="#">29 70 44 2</a>	50
<b>Base element</b> , 11.25 mm wide	 UMK-BE 11,25	<a href="#">29 71 53 5</a>	10
<b>Base element</b> , 22.5 mm wide	 UMK-BE 22,5	<a href="#">29 70 02 8</a>	10
<b>Base element</b> , 45 mm wide	 UMK-BE 45	<a href="#">29 70 01 5</a>	10
<b>Foot element</b> , for mounting on 4 or 3, is plugged between base and side elements	 UMK-FE	<a href="#">29 70 03 1</a>	10
<b>Accessories</b>			
<b>Mounting ear</b> , for mounting directly on the wall	 UMK-BF	<a href="#">29 76 07 7</a>	50

## Type of housing

Polyamide PA see [product-line info](#)

Inflammability class V2 (UL 94) color: green

Further Technical Information see "Family-info".

## Dimensional drawing

