

# T-1<sup>3</sup>/<sub>4</sub> (5 mm) Right Angle LED Indicator Options

## Technical Data

### Option B2 Option B1


#### Features

- Ideal for Card Edge Status Indication
- Package Design Allows Flush Seating on a PC Board
- May be Side Stacked on 6.35 mm (0.25") Centers
- LEDs Available in Four Colors, With or Without Integrated Current Limiting Resistor in T-1<sup>3</sup>/<sub>4</sub> Tinted Diffused Packages


- Housing Meets UL9V-0 Flammability Rating
- Additional Catalog Lamps Available as Options

#### Description

The T-1<sup>3</sup>/<sub>4</sub> Option B2 and B1 series of Right Angle Indicators are industry standard status indicators that incorporate a T-1<sup>3</sup>/<sub>4</sub> LED lamp in a black plastic right angle mount housing. The indicators are available in

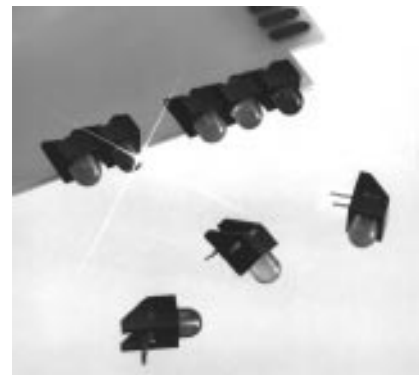

#### Package Dimensions

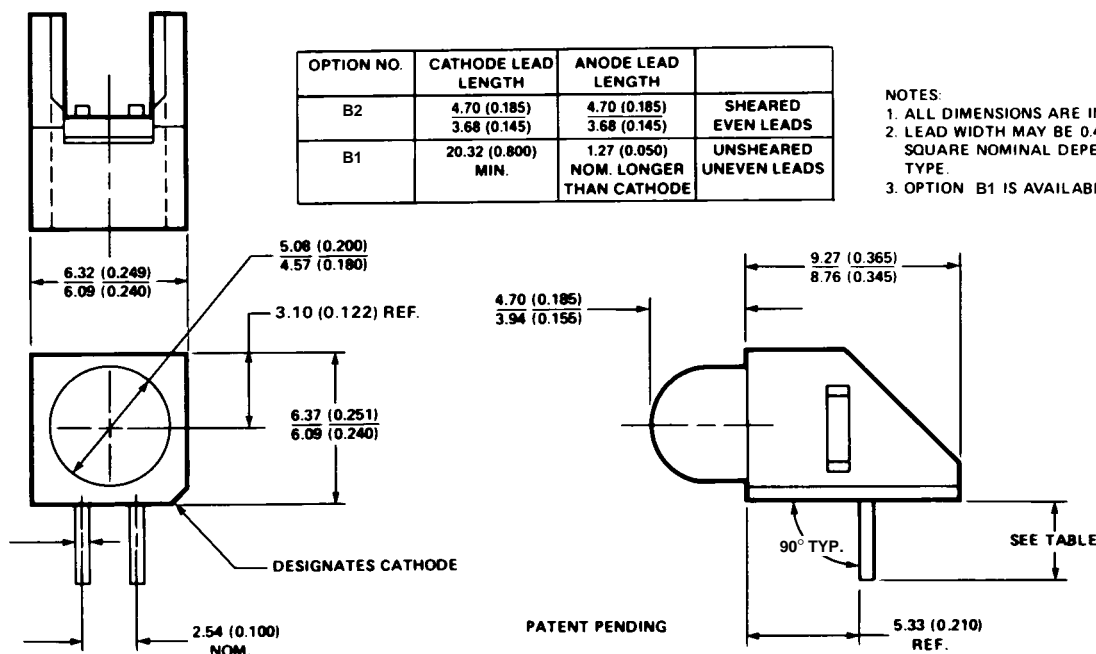

standard Red, High Efficiency Red, Yellow, or High Performance Green with or without an integrated current limiting resistor. These products are designed to be used as back panel diagnostic indicators and card edge logic status indicators.

### **Ordering Information**

To order T-1<sup>3/4</sup> high dome lamps with right angle mount housing, select the base part number and

add the option code B2 or B1. For example: HLMP-3750-L00B2 option B2.

All Hewlett-Packard T-1<sup>3/4</sup> high-dome lamps are available in right angle housing. Contact your local Hewlett-Packard Sales Office or authorized components distributor for additional ordering information.

The Plastic right angle housing may be purchased separately as part number HLMP-5029.

### **Absolute Maximum Ratings and Electrical/Optical Characteristics**

The absolute maximum ratings and device characteristics are identical to those of the T-1<sup>3/4</sup> LED lamps. For information about these characteristics, see the data sheets of the equivalent T-1<sup>3/4</sup> LED lamp.

*[www.hp.com/go/led](http://www.hp.com/go/led)*

For technical assistance or the location of your nearest Hewlett-Packard sales office, distributor or representative call:

**Americas/Canada:** 1-800-235-0312 or 408-654-8675

**Far East/Australasia:** Call your local HP sales office.

**Japan:** (81 3) 3335-8152

**Europe:** Call your local HP sales office.

Data subject to change.

Copyright © 1999 Hewlett-Packard Co.

Obsoletes 5964-9297E (4/96)

5968-4123E (3/99)