




## G2G120 Series Centrifugal

Single inlet centrifugal blower with brushless DC motor mounted inside the scroll housing for better performance and compact form/fit

Part Number	CFM @ 0	Curve	Volts	Voltage Range	Watts	dBa	Temp. Max C	Wgt. (oz)	Type Of Bearing	Features	Insul. Class
G2G120-AB17-52	130	1	24	16 to 28	40	58	60	72	Ball	Flange	R
G2G120-AR31-01	130	1	12	8 to 14	40	58	60	72	Ball	Flange	R

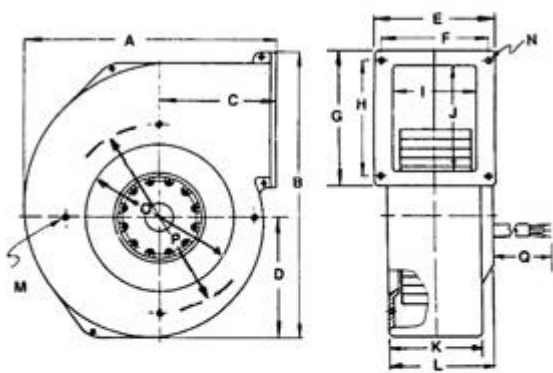

DIMENSIONS - inches (mm)

PART NUMBER	A	B	C	D	E	F	G	H	I	J	K	L	M	N	O	P	Q
G2G120	6.85 (174)	7.48 (190)	3.23 (82)	3.23 (82)	4.53 (115)	3.94 (100)	3.27 (83)	2.68 (68)									
									2.99 (76)	1.97 (50)	3.23 (82)	3.86 (98)	M4	.28 (7)	3.94 (100)	5.20 (132)	17.72 (450)

