


Product Description

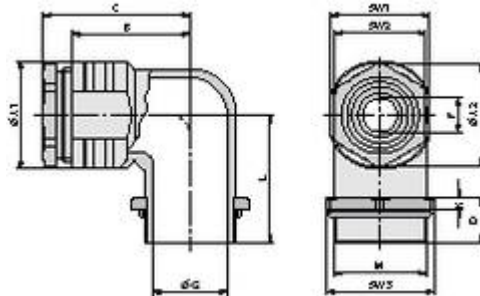

Application

Angle gland with compact dimensions with metric connection thread according to EN 50262. Seawater resistant, resistant against tropical conditions and corrosion, also when used in combination with grey cast iron or steel. The adjusting nut enables the SKINDICHT® RWV-M to be fastened in any position.

Note

- Combination with different conduit glands possible
- Counter nut to be used SKINDICHT® SM-M

Technical Data

Material

Body: Zinc die casting, nickel plated Compression
 screw / hexagon nut: nickel plated brass Incised
 sealing ring: CR/NBR O-ring: NBR

Range of temperature

-20°C up to +100°C

Degree of protection

IP 55

Article List

Part number	Part designation / size	Clamping range ØF mm	L	SW1	Ø A1	SW2	Ø A2	Ø G	Height mm	Overall length C mm	Thread length D mm	SW3	Pieces / VPE
SKINDICHT® RWV-M													
52107800	12 x 1,5	5	20,5	14	16	12	13,2	8	5	26,1	11,5	17	25
52107810	16 x 1,5	9 - 3	23,5	18	20	16	17,6	12	5	28,6	11,5	22	25
52107820	20 x 1,5	13 - 4	28,5	22	24	20	22,2	15	5	35,1	12,5	27	25
52107830	25 x 1,5	17,5 - 8,5	31	27	29	25	27,5	20	5	38,1	13,5	32	10
52107840	32 x 1,5	25 - 16	36	34	36	32	35,2	27	5	44,6	13,5	41	10
52107850	40 x 1,5	32 - 23	45	42	45	40	43,5	35	5	53,1	15,5	46	5