 


Twist Tail™



No tool needed

Thomas&Betts



Looking for a cable tie fast and easy to install, without using an extra tool?


The new Twist Tail™ Cable Tie

How does it work?

Wrap the Twist Tail™ cable tie around the bundle of cables, bend the excess tail in two directions and twist!

The tail breaks right off, leaving no sharp edges to scratch your hands or your cables.

It's as simple as that.

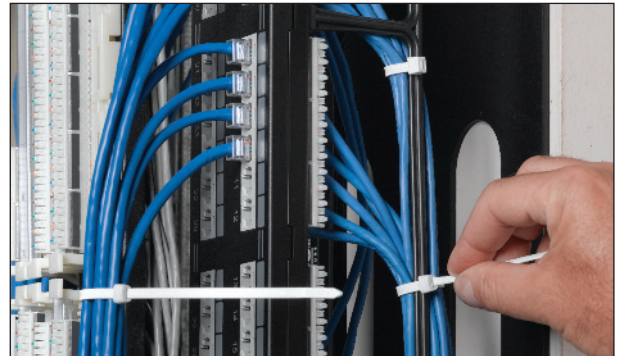

Features & Benefits

- New all-plastic cable tie, with unique, patent pending design
- Quick and easy to install, no tools required
- Strong, made of Polyamide 6.6, with 220N minimum tensile strength
- Safe, tail breaks off neat and clean, with no sharp edges
- General purpose applications, indoor and outdoor
- UL recognised
- Available in 3 different lengths and 2 colours (white and UV-resistant black)



E49405

Technical Information

Material	Polyamide 6.6
Temperature range	-40°C to +85°C
Colour	White or UV-resistant black
Flammability rating	UL 94 V-2
Other properties	Halogen free, Silicone free, UV resistant (black)



Product Ref.	Colour	Length [mm]	Width [mm]	Thickness [mm]	Max. bundle diameter [mm]	Minimum tensile strength [N]	Quantity [pieces]
TT-7-50-9-C	white	180	4.7	1.4	44	220	100
TT-7-50-0-C	black	180	4.7	1.4	44	220	100
TT-11-50-9-C	white	282	4.7	1.4	76	220	100
TT-11-50-0-C	black	282	4.7	1.4	76	220	100
TT-14-50-9-C	white	358	4.7	1.4	102	220	100
TT-14-50-0-C	black	358	4.7	1.4	102	220	100