

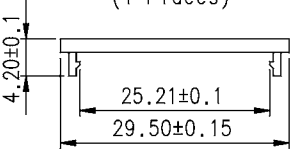
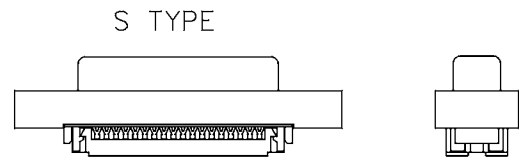
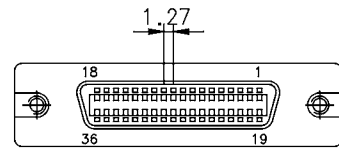
 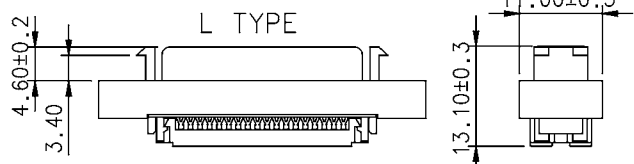



Termination Cover  
(1 Places)

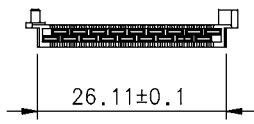

Wire Holder  
(2 Places)



- FEATURES:**
- Half pitch 1.27mm(.050") series
  - Centronic type female connector For 1.27mm(.050") ribbon cable
  - Panel mount receptacle assemblies bracket with latch block and without latch block
  - Die-Cast body provide EMI/RFI shielded
- MATERIALS:**
- Housing And Cover: Plastic thermoplastic P.B.T UL94V-0 black
  - Contact: Phosphor bronze gold selective plated
  - Bracketshell: Die-Cast zinc nickel plated over copper
- ELECTRICAL:**
- Current Rating: 1 Amp
  - Insulation Resistance: 500M  $\Omega$ /in
  - Withstanding Voltage: 500V AC/Min
  - Contact Resistance: 35m  $\Omega$ max
  - Temperature Range: -55°C ~ +105°C

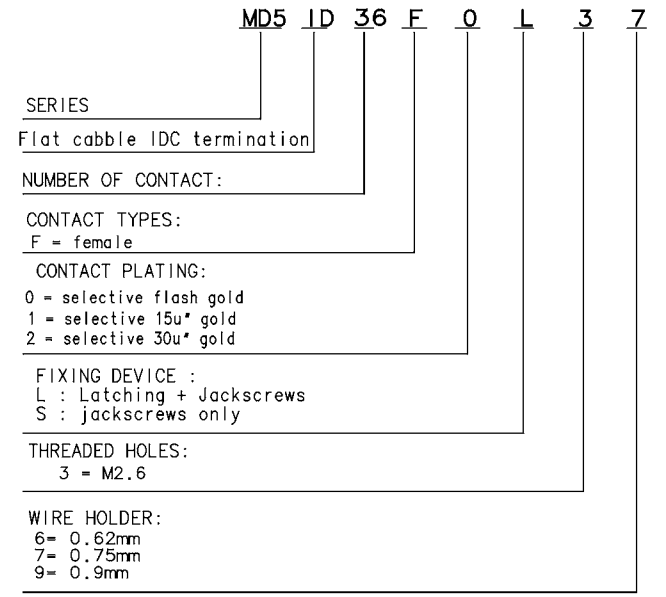

Amphenol Socapex Usine de Dole		TOL. GEN.							
		VOLUME PIECE							
		SURFACE PIECE							
		PROTECTION							
		TRAITEMENT							
		MATIERE							
ECH. 1,5 ENS.		DOSSIER							
N SERIE		CLIENT	A	CREATION PLAN	ATO	30/05 2005	ATO	A	X
DATE DU TIRAGE	DESIGNATION	MODIFICATIONS		EXEC.		DATE	Approb		IND.
	MINI D SERIES	N INTERNE							