


 















Euromas II, lid with membrane area

**Product no.:** 63205200  
**Length:** 52  
**Width:** 50  
**Height:** 37  
**Material:** ABS (acrylonitrile-butadiene-styrene)  
**Sealing material:** Neoprene  
**Color:** light grey  
**Ingress protection:** IP 65  
**PDF:**   
**DXF:** 

**Accessories:**

Product no.	Model	Description
22009000	GF	  Rubber feet, Polyurethane, black, 65-75 Shore, 1 set = 4 pcs.
22080000	SA	screw covers (6 pcs), for Euromas II
22010000	EM-WL	  wall bracket set = 4 pcs, for Euromas II
22000100	M	  Mounting plate, for Euromas M/T 205

Ausführung EM/ET 205 F

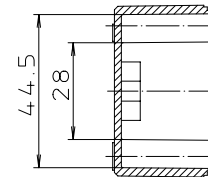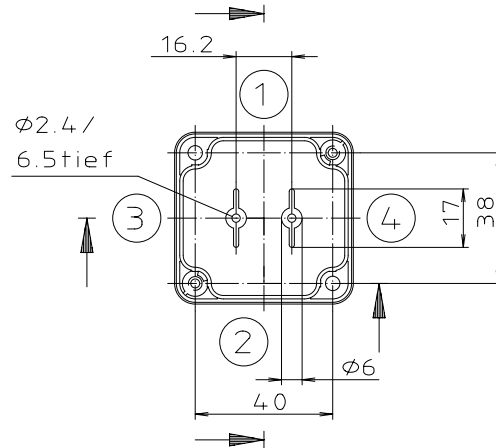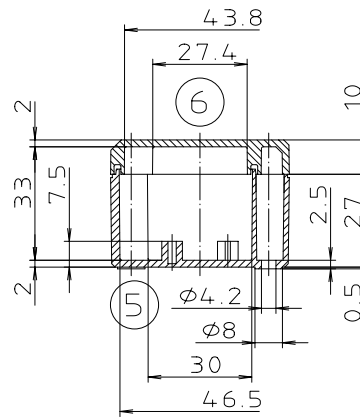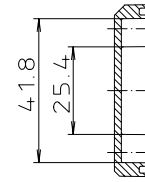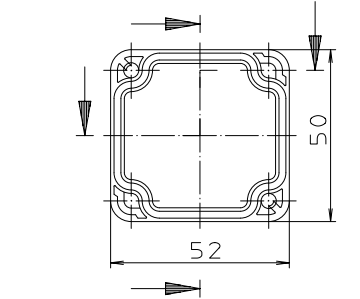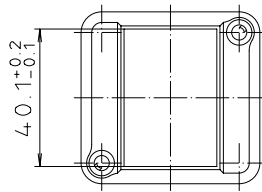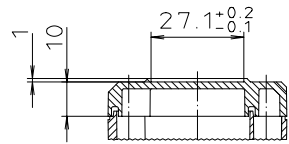

"Schutzvermerk nach DIN 34 beachten"

Maßstab : 1:1		
Zchn.Nr.: ZG 5145.026.04		
Artikel: EM/ET 205 EM/ET 205 F Katalogzeichnung		
3633 22.08.02 2795 01.03.93 2722 08.01.93		DISK : 2 500 872 Datum: 02.07.92 OK