




Safe-Ty™

SF175-50-100

Low profile in-line tie ideal for use where precision bundling is required and clearance is a necessity.

T&B Catalog Number: SF175-50-100
EAN Number: 05414363130048
UPC Number: 78621099665
Description: All-plastic, low profile in line cable tie, 201 x 4.7 mm, natural Polyamide 6.6

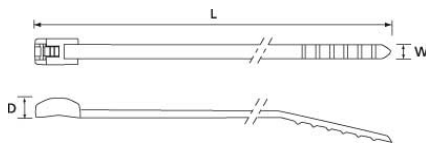

Technical Information

Type	low profile in line
Material	Polyamide 6.6
Temperature Range	-40°C to +85°C
Flammability Rating	UL 94 V-2
Colour	natural
Halogen free	yes
Silicone free	yes

Ordering Information

Length (mm)	201
Width (mm)	4.7
D (mm)	4.5
Max. Bundle Diameter (mm)	44.5
Min. Bundle Diameter (mm)	4.7
Min. Tensile Strength (N)	220
Quantity (pieces)	100
Packaging Type	bag
Storage Conditions	Nylon (Polyamide) is inherently susceptible to environmental conditions. Polyamide 6.6 cable ties are moisturised to optimum performance levels at machine-side and should be stored in cool dry areas out of direct sunlight. Cable ties are packaged in plastic bags to contain moisture and should remain sealed until ready for use.

Tooling	ERG299, ERG 297, WT193A, L-500-EU
Note	For other colours please contact your Customer Service