
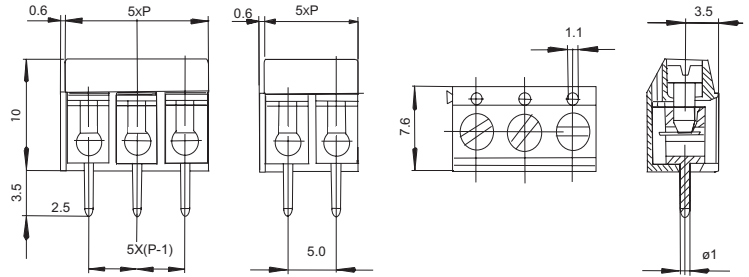


5mm Pitch Low Profile Screw Terminal

- 2 & 3 pole interlocking
- Test probe facility
- Moulded in black UL94V-0 PA (GF)
- Wire protector terminals
- UL approved
- Guided pin alignment

CTB5202 series

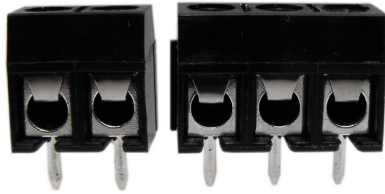



Type No.	Poles	Length
CTB5202/2	2	10mm
CTB5202/3	3	15mm
CTB5202/4	4	20mm
CTB5202/5	5	25mm
CTB5202/6	6	30mm
CTB5202/7	7	35mm
CTB5202/8	8	40mm
CTB5202/9	9	45mm
CTB5202/10	10	50mm
CTB5202/11	11	55mm
CTB5202/12	12	60mm

Rating	300V/15A
Insulation resistance	5000M Ω at 1000V
Operating temperature	-33°C to 120°C
Cable entry	1.5mm ²
Withstand Voltage	AC2000/1Min
Recommended PCB hole size	ϕ 1.2mm

5 mm Pitch Low Profile 90° Terminal Block

- 2-3 pole interlocking
- Test probe facility
- Wire protector terminals
- Moulded in black UL94V-0
- Guided pin alignment
- 1.5mm² cable entry
- UL approved

CTB5252 series

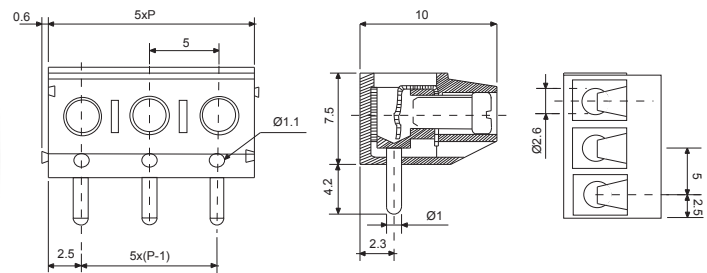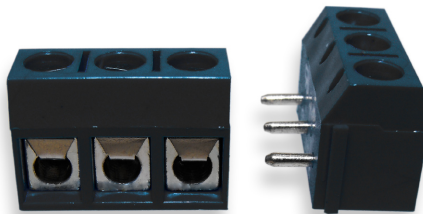

Type No.	Poles	Length
CTB5252/2	2	10mm
CTB5252/3	3	15mm
CTB5252/4	4	20mm
CTB5252/5	5	25mm
CTB5252/6	6	30mm
CTB5252/7	7	35mm
CTB5252/8	8	40mm
CTB5252/9	9	45mm
CTB5252/10	10	50mm
CTB5252/11	11	55mm
CTB5252/12	12	60mm

Rating	300V/15A
Insulation resistance	5000M Ω at 1000V
Operating temperature	-33°C to 120°C
Cable entry	1.5mm ²
Withstand Voltage	AC2000V/1Min
Recommended PCB hole size	ϕ 1.2mm