


Product Presentation



- Snap-in connector - approx. 16 mm diameter
- IP 67
- Attractive price
- Modular design (contact insert of cable connector and chassis sockets are identical)
- 3 cable outlet ranges: approx. ca.2,5-4mm, 4-6mm, 6-8mm
- 3, 5, 8, 12 pole versions
- Delivery: available

Explosion picture

- Cable connector

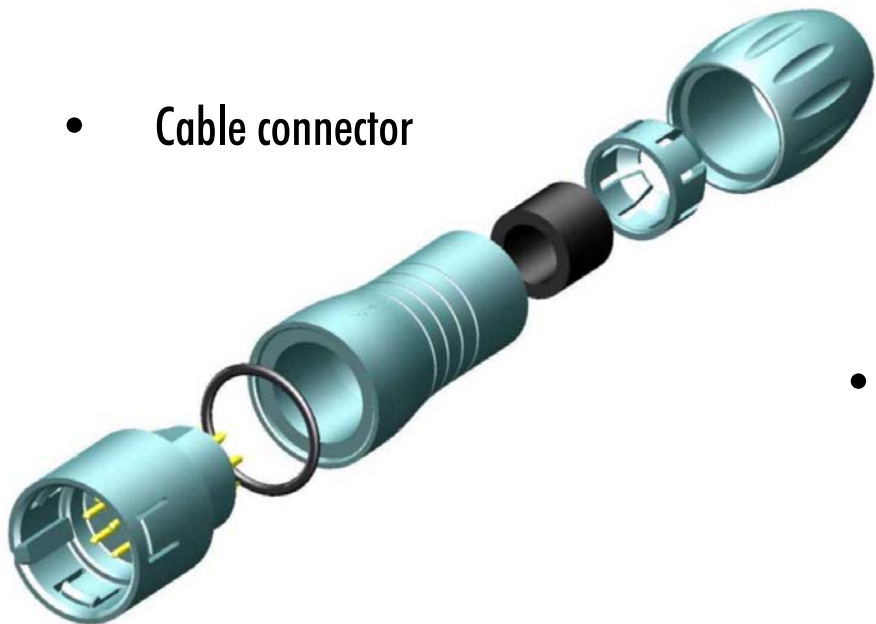

- Female socket
(immersed assembly
possible with
adapter)



- male socket adapter in
two versions (front and
back assembly)



Technical data :

Number of contacts :	3	5	8	12
Locking :	snap-in			
Termination mode :	solder			
Wire gauge :	0,75 mm ²		0,25 mm ²	
Degree of protection:	IP 67			
Connector diameter:	16 mm (cable outlet 2,5 - 4 mm, 4-6 mm), 19 mm (cable outlet 6-8 mm)			
rated voltage :	250 V	125 V	125 V	60 V
pollution degree :	2			
overvoltage category	II			
rated current :	7 A	5 A	2 A	2 A
contact plating:	AG (silver)		AU (gold)	
Housing, insert:	PA 66 (UL 94 V0)			