

NO MERCURY ADDED


Description	: Mercury Free Extra Heavy Duty Battery, AAA Size
Chemical System	: Zinc Chloride
Nominal Voltage	: 1.5 Volts
Nominal Dimensions	: Ø10.5 mm x 44.5 mm
Terminals	: Protruded positive(+) and flat negative(-) contacts
Jacket	: Printed PVC shrink sleeve
Applications	: All electronic devices, e.g. toys, photographic equipment, data banks, calculators, audio appliances, remote controls, paging machines.
Warranty Period	: 36 months
Average Weight	: 8.7g

Cross References:



GP	JIS	IEC	Eveready
24G	R03	R03	1212

Typical Service Life:

Discharge Resistance	Discharge Condition	End Point Voltage	Service Life
15 Ohms	24 Hrs/ Day	0.9V	275 Mins

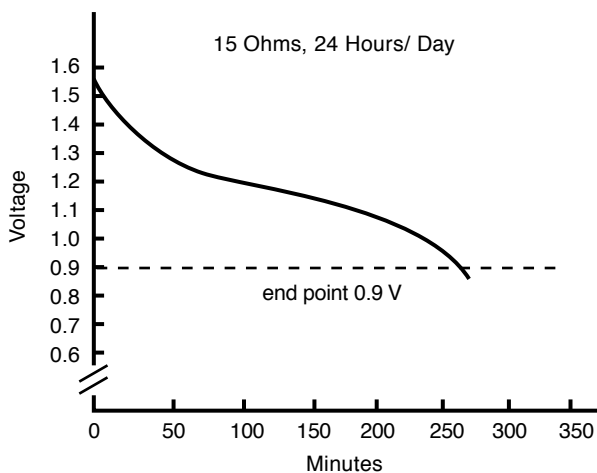

Model No.: **GP24G**

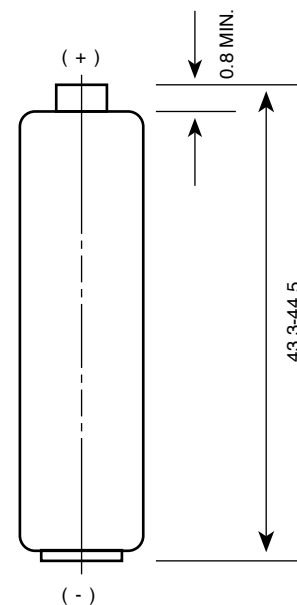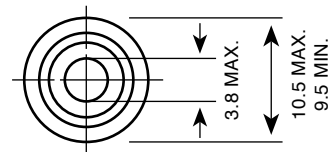

Unit : mm

The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.

www.gpbatteries.com

Manufacturer reserves the right to alter or amend the design, model and specification without prior notice.
Copyright© GPI International Ltd. - All rights reserved

Member
Gold Peak Group

04060105087