

NO MERCURY ADDED


Description	: Mercury Free Extra Heavy Duty Battery, C Size
Chemical System	: Zinc Chloride
Nominal Voltage	: 1.5 Volts
Nominal Dimensions	: Ø26.2 mm x 50 mm
Terminals	: Protruded positive(+) and flat negative(-) contacts
Jacket	: Metal jacket with PVC tube insulation
Applications	: All electronic devices, e.g. transistor radios, cassette recorders, toys, alarm clocks, lighting, torches & portable fans.
Warranty Period	: 24 months
Average Weight	: 49g

Cross References:



GP	JIS	IEC	Eveready
14G	R14P	R14P	1235

Typical Service Life:

Discharge Resistance	Discharge Condition	End Point Voltage	Service Life
3.9 Ohms	24 Hrs/ Day	0.9V	320 Mins

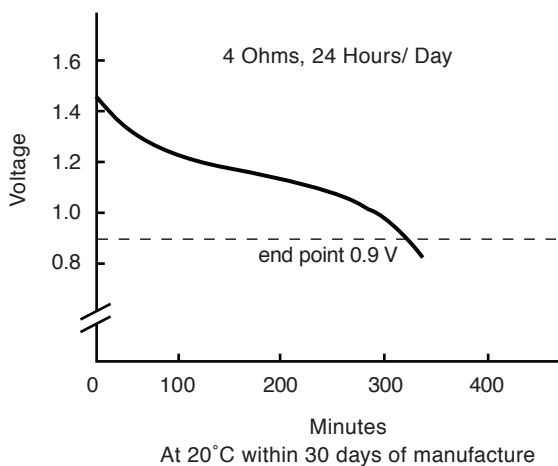

Model No.: **GP14G**

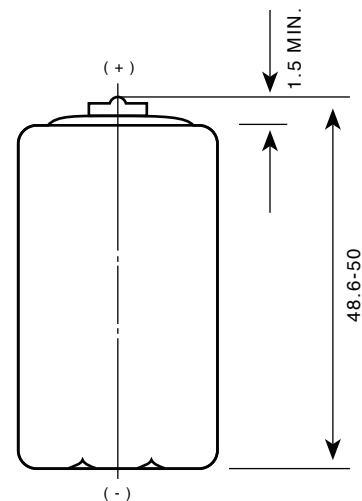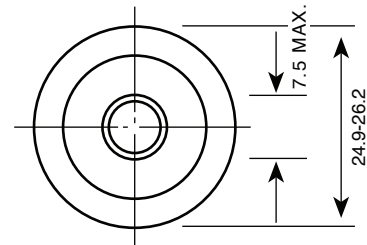

Unit : mm

The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.